

Rail Four Post Terminal Block



VLASTNOSTI

Separates "clean" wiring from "dirty" wiring

Includes integrated test terminal

Includes slot for low-impedance busbar

Modular design for field assembly and future expansion

Meets AAR recommendations

SPECIFIKACE

Table 1/2

Katalogové číslo	Length (L)	Hloubka (D)	Height (H)	A	B	Thread Size (TS)
B2700A2C1WH	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS
SBB2700A2B10	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS

Table 2/2

Katalogové číslo	Hardware Included
B2700A2C1WH	Yes
SBB2700A2B10	No


DALŠÍ PODROBNOSTI O PRODUKTU

B2700A2C1WH kit includes: (1) terminal block, (1) offset test link, (15) 9/16" outer diameter copper flat washers, (9) zinc plated binding 14-24 UNS-2B hex nuts AAR, (5) nickel plated jam 14-24 UNS-2B hex nuts AAR, (2) #10X1 – 1/2" zinc plated screws, and (1) instruction print.

Four Post Terminal Blocks are components included in nVent ERICO pre-engineered and manufactured panels.

Design assistance is available for special applications. Contact your nVent ERICO representative for more details.

DIAGRAMS

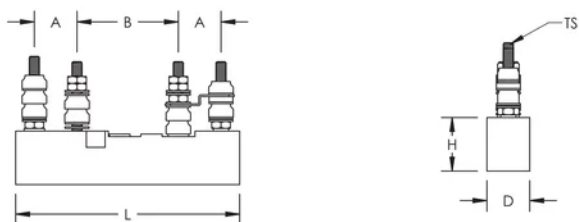

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE