


Rebar Grounding Clamp, Heavy Duty



CERTIFICATIONS

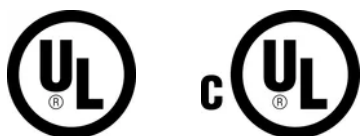

VLASTNOSTI

Provides two connection points to concrete encased electrodes (rebar) for states where the Authority Having Jurisdiction (AHJ) requires it

Meets 2005 NEC® standard requirement for bonding to rebar into the grounding system

Suitable for direct burial applications

Has high-strength bronze alloy construction

Easy to install

SPECIFIKACE


Materiál: Bronze

Table 1/1

Katalogové číslo	Article Number	Conductor Size	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Certifications
RC70	710325	#8 Solid - 2/0 Stranded, 10 mm² Stranded - 70 mm² Stranded	8 - 18 mm	#3 – #6	10M – 20M	UL

Katalogové číslo	Article Number	Conductor Size	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Certifications
RC100	710335	#8 Solid - 4/0 Stranded, 10 mm² Stranded - 100 mm² Stranded	18 - 36 mm	#6 – #11	20M – 35M	UL, cUL

DIAGRAMS

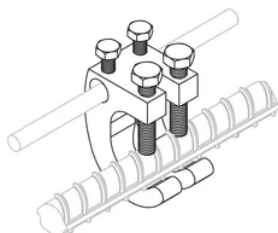

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE