

Rebar Grounding Clamp, Perpendicular



CERTIFICATIONS



VLASTNOSTI

Universal use for rebar, rods or pipes

Lay-in feature cuts installation time

Bronze alloy construction with Stainless Steel 304 screws

Approved for direct burial in earth and concrete

SPECIFIKACE

Table 1/2


Katalogové číslo	Article Number	Materiál	Typ připojení	Conductor Size	Ground Rod Diameter, Actual (Ø)	Water Pipe Size (Ø)
EK17	710365	Bronze, Stainless Steel 304 (EN 1.4301)	Perpendicular	#10 Solid - #2 Solid, 5.5 mm ² Stranded - 25 mm ² Stranded	12.7 - 25.4 mm	12.7 - 25.4 mm

Table 2/2

Katalogové číslo	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada
------------------	----------------	--------------------	----------------	--------------------

EK17	710365	12 - 25 mm	#4 – #8	10M – 25M
------	--------	------------	---------	-----------

DIAGRAMS

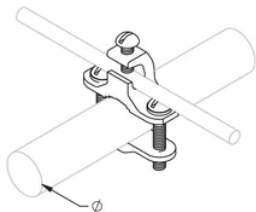

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE