

Universal Transient Barrier, Modem/Telephone



CERTIFICATIONS



VLASTNOSTI

General purpose barrier provides protection of low-voltage circuits and transducers

Separate plug and base design allows hot swappable module replacement


Multi-stage protection and fine over-voltage protection helps ensure lowest residual surge voltages reach sensitive equipment

SPECIFIKACE

Katalogové číslo	UTBTA
Article Number	702850
Max Continuous Operating Voltage (Uc)	280 V
Rated Load Current (IL)	160mA
Frequency	15 MHz
Loop Resistance	1 Ω
Max Discharge Current (Imax), Per Mode	0.5kA 8/20 μs
Technology	Gas Discharge Tube (GDT) PTC

Katalogové číslo	UTBTA
Voltage Protection Level (Up), L-L	480 V @ 3 kA
Connection, Stranded	1 - 4 mm ²
Mounting	35 mm top hat DIN rail
Temperature	-20 to 65 °C
Enclosure Material	UL® 94V-0 Thermoplastic
Enclosure Rating	IP 20 NEMA®-1
Hloubka (D)	68mm
Height (H)	90 mm
Width (W)	18 mm
Unit Weight	0.1 kg
Certification Details	UL® 497A
Complies With	ANSI®/IEEE® C62.41.2-2002 Cat A, Cat B, Cat C
Replacement Module	UTBTM

DIAGRAMS

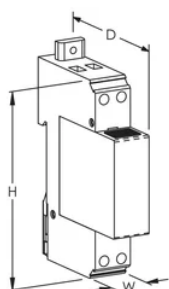

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE