

EBC-133 Main Terminal Clamp Kit



CERTIFICATIONS



VLASTNOSTI

Kit includes 10 clamps and 20 screws

Used to connect thicker conductors including IBSB25 Insulated Braided Conductor, MJB Grounding and Bonding Braid, and nVent ERIFLEX Flexibar up to 9 mm (0.354")

Quick and easy installation

RoHS compliant

SPECIFIKACE

Table 1/2


Katalogové číslo	Article Number	Materiál	Povrchová úprava	Conductor Size, IEC	Width (W)	Thickness (T)
KIT-EBC133-15	568614	Ocel	Electrogalvaniz ed	16 - 35 mm ²	25 mm	2.5 mm

Table 2/2

Katalogové číslo	Article Number	A	Hole Size (HS)	Thread Size (TS)	Unit Weight	Hloubka (D)

KIT-EBC133-15	568614	15 mm	5.5 mm	M5	0.01 kg	10mm
---------------	--------	-------	--------	----	---------	------

DIAGRAMS

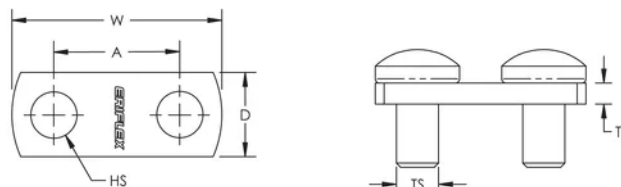

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE