


PB Lug for Flat Braids

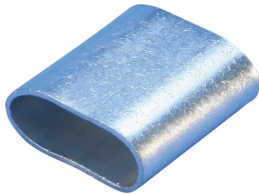

CERTIFICATIONS



VLASTNOSTI

Crimp to FTCB or FRCB braids to create custom flexible connections

Crimped and drilled using BD Crimp and Drill Tool or Crimping Tool for Hydraulic Work Center

RoHS compliant


SPECIFIKACE

Materiál: Copper

Povrchová úprava: Tinned

Table 1/1

Katalogové číslo	Article Number	Cross Section	Width (W)	Length (L)	Thickness (T)	Unit Weight
PALM-16	557180	16mm ²	16 mm	15mm	1 mm	0 kg
PALM-25	557190	25mm ²	22 mm	25mm	1 mm	0.01 kg
PALM-50	557380	50mm ²	30 mm	30mm	1 mm	0.02 kg

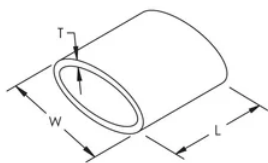

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte