


RTCBI Insulated Round Braid in Coil, Tinned Copper

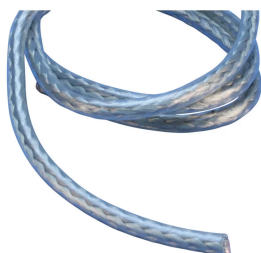

CERTIFICATIONS



VLASTNOSTI

Braids in coil are mainly used for power distribution or earthing applications

Non-magnetic material

Tinned finish provides a theft-deterrent appearance

SPECIFIKACE

Materiál: Copper;Polyvinylchloride

Povrchová úprava: Tinned

Table 1/2

Katalogové číslo	Article Number	Nominal Current	Cross Section	Number of Wires	Wire Diameter	Length
RTCBI15-10	503400	75A	10mm ²	560	0.15mm	25m
RTCBI15-16	503410	120A	16mm ²	900	0.15mm	25m

Katalogové číslo	Article Number	Nominal Current	Cross Section	Number of Wires	Wire Diameter	Length
RTCB115-25	503420	150A	25mm ²	1416	0.15mm	25m
RTCB115-30	503430	180A	30mm ²	1680	0.15mm	25m
RTCB115-50	503440	250A	50mm ²	2820	0.15mm	25m

Table 2/2

Katalogové číslo	Article Number	Diameter	Unit Weight
RTCB115-10	503400	7 mm	0.12 kg
RTCB115-16	503410	8 mm	0.18 kg
RTCB115-25	503420	9.5 mm	0.25 kg
RTCB115-30	503430	10 mm	0.35 kg
RTCB115-50	503440	12.5 mm	0.58 kg

Insulation Thickness: 1 mm
Insulation Voltage: 450V
Flammability Rating: UL® 94V-0
Temperature: 70 °C Max

DALŠÍ PODROBNOSTI O PRODUKTU

Unit weight is per meter (3.28').

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE