

UFS nVent ERIFLEX Flexibar and IBSB Support Kit



CERTIFICATIONS



VLASTNOSTI

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Materiál	Conductor Thickness	Conductor Width	Height (H)	Length (L)
UFS-KIT	553590	Aluminum, Polyamide	2 - 8 mm	15.5 - 120 mm	57.5 mm	2000mm

Table 2/2


Katalogové číslo	Article Number	Width (W)	A	B	Unit Weight
------------------	----------------	-----------	---	---	-------------

UFS-KIT	553590	30 mm	24 mm	15 mm	2.3 kg
---------	--------	-------	-------	-------	--------

DALŠÍ PODROBNOSTI O PRODUKTU

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

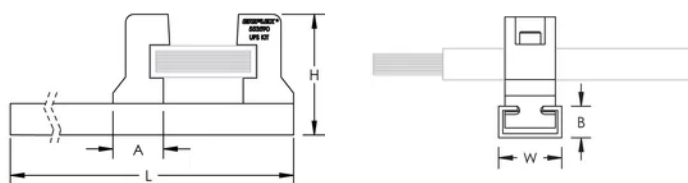

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE