


Universal Busbar Support with Neutral Circuit, High Ampacity

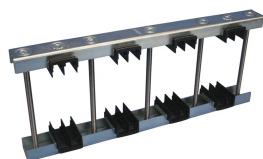

CERTIFICATIONS



VLASTNOSTI

Universal fixing system

Installs quickly and easily

Extremely robust construction

Screws are made from non-magnetic stainless steel

Halogen free insulators

SPECIFIKACE

Max Working Voltage, IEC (Ui):	1000;1500
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C


Table 1/2

Katalogové číslo	Article Number	Materiál	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness
UBS2-10TN-160	561870	Ocel, Glass Fibre Reinforced Polyamide	5700 A	1 - 2	160 mm	10 mm
UBS2-10TN-200	561880	Ocel, Glass Fibre Reinforced Polyamide	5700 A	1 - 2	200 mm	10 mm
UBS3-10TN-160	561540	Ocel, Glass Fibre Reinforced Polyamide	6200 A	1 - 3	160 mm	10 mm
UBS1-10TN-160	561500	Ocel, Glass Fibre Reinforced Polyamide	3500 A	1	160 mm	10 mm

Table 2/2

Katalogové číslo	Article Number	Width (W)	A
UBS2-10TN-160	561870	480 mm	110 mm
UBS2-10TN-200	561880	480 mm	110 mm
UBS3-10TN-160	561540	480 mm	110 mm
UBS1-10TN-160	561500	300 mm	70 mm

DIAGRAMS

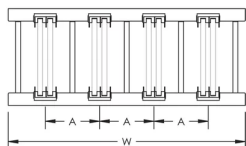

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE