


Lille gennemføringstykke 2-3mm

KATALOGOVÉ ČÍSLO

CCFGS11

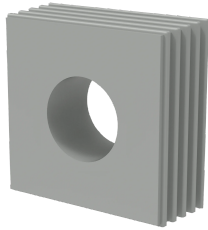

CCFGS cable glands are used with CCFI, CCFO and CCFR cable entry systems.

PRŮMYSLOVÉ NORMY

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

VLASTNOSTI

IP66 Modular Halogen-free and silicone free cable entry system, that provide versatility, variability and variety

Everything mounted from the outside of the enclosure

The frames, inlays and grommets can be combined in many ways - ensuring you many versatile configuration options

The frame does not need to be disassembled if requirements change or carrying out service work

No need to disassemble and reconnect connectors on cables so manufactures warranty is not voided

The conical shape of the grommets allows them to be easily pressed in, provides static strain relief in accordance with DIN EN 62444

For assembly, they are pressed from the inside out into the openings of the assembled inlays

The grommets are available in different sizes to match the diameter of the cable

The CCFGs is first placed around the cable and then inserted into the cable gland

Based on the wave-cut profile, there is no need to remove the connector on the assembled cabled

VLASTNOSTI PRODUKTU

Výška: 20.3mm

Šířka: 20.3mm

Hloubka: 17.7mm

Materiál: Plast

Povrchová úprava: Untreated

Barva: Gray

Provozní teplota: -40 to 90°C

Hmotnost: 0.00589569160997732kg

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE