


Vertical rear busbar supports | Power Distribution, MSFH

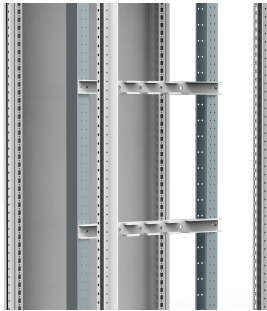

This fix system vertical busbar support, MSFH, for two bars up to 40 x 10 mm, is available off the shelf and has been tested according to IEC 61439.

VLASTNOSTI

Popis: Busbar supports up to 1600A to be mounted vertically behind the fixed compartments. Mounts to the vertical profiles MSFP. Rated short-time withstand current up to 35 kA with rear supports and up to 50 kA with rear and front supports.

Materiál: Polycarbonate reinforced with 10% of glass material.

Dodávka: 7 busbar supports for 3 phases and neutral, and mounting material.

A flexible and reliable solution that ensures procurement, design and installation can be done efficiently reducing the labour time required

Fix system vertical profiles (MSFP) are required in order to mount the busbar supports

Busbar supports up to 1600A to be mounted vertically behind the fixed compartments

Mounts to the vertical profiles MSFP

Rated short-time withstand current up to 35 kA with rear supports and up to 50 kA with rear and front supports

Delivery: 7 busbar supports for 3 phases and neutral, and mounting material

SPECIFIKACE

Table 1/1						
Katalogové číslo	Výška	Šířka	Hloubka	Enclosure Material	Produktová řada	Materiál
MSFH06	40mm	600mm	45mm	Ocelový Plech	Free-Standing	Polycarbonate

DALŠÍ PODROBNOSTI O PRODUKTU

*In: Rated current. *Icw: Rated short-time withstand current.

*In: Rated current. *Icw: Rated short-time withstand current.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE