

# A12 Standard Transition Coupler, Plain, Worldwide Design



## CERTIFICATIONS



## VLASTNOSTI

Designed to splice different diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

Installs quickly and easily

## SPECIFIKACE

|                          |                                          |
|--------------------------|------------------------------------------|
| <b>Povrchová úprava:</b> | Plain                                    |
| <b>Materiál:</b>         | Ocel                                     |
| <b>Design Version:</b>   | Worldwide (Globally Available Materials) |

Table 1/2

| Katalogové číslo | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Hex Width (W) | Diameter (Ø) | Length (L) |
|------------------|--------------------|----------------|--------------------|---------------|--------------|------------|
|------------------|--------------------|----------------|--------------------|---------------|--------------|------------|

|            |              |        |          |       |  |      |
|------------|--------------|--------|----------|-------|--|------|
| EL1210A12N | 12 mm, 10 mm | #4, #3 |          | 17 mm |  | 55mm |
| EL1614A12N | 16 mm, 14 mm |        |          | 22 mm |  | 64mm |
| EL1412A12N | 14 mm, 12 mm |        |          | 22 mm |  | 57mm |
| EL1612A12N | 16 mm, 12 mm | #5, #4 | 15M, 10M | 22 mm |  | 61mm |
| EL1410A12N | 14 mm, 10 mm |        |          | 22 mm |  | 57mm |
| EL1610A12N | 16 mm, 10 mm | #5, #3 |          | 22 mm |  | 61mm |
| EL1812A12N | 18 mm, 12 mm |        |          | 27 mm |  | 66mm |
| EL1816A12N | 18 mm, 16 mm |        |          | 27 mm |  | 71mm |
| EL1810A12N | 18 mm, 10 mm |        |          | 27 mm |  | 66mm |
| EL1814A12N | 18 mm, 14 mm |        |          | 27 mm |  | 69mm |
| EL2012A12N | 20 mm, 12 mm | #6, #4 | 20M, 10M | 27 mm |  | 74mm |
| EL2014A12N | 20 mm, 14 mm |        |          | 27 mm |  | 77mm |
| EL2010A12N | 20 mm, 10 mm | #6, #3 |          | 27 mm |  | 74mm |
| EL2016A12N | 20 mm, 16 mm | #6, #5 | 20M, 15M | 27 mm |  | 80mm |
| EL2018A12N | 20 mm, 18 mm |        |          | 27 mm |  | 85mm |
| EL2212A12N | 22 mm, 12 mm | #7, #4 |          | 30 mm |  | 77mm |
| EL2216A12N | 22 mm, 16 mm | #7, #5 |          | 30 mm |  | 83mm |
| EL2210A12N | 22 mm, 10 mm | #7, #3 |          | 30 mm |  | 77mm |
| EL2214A12N | 22 mm, 14 mm |        |          | 30 mm |  | 80mm |

|            |              |        |          |       |       |       |
|------------|--------------|--------|----------|-------|-------|-------|
| EL2218A12N | 22 mm, 18 mm |        |          | 30 mm |       | 87mm  |
| EL2220A12N | 22 mm, 20 mm | #7, #6 |          | 30 mm |       | 95mm  |
| EL2512A12N | 25 mm, 12 mm | #8, #4 | 25M, 10M |       | 35 mm | 81mm  |
| EL2514A12N | 25 mm, 14 mm |        |          |       | 35 mm | 83mm  |
| EL2510A12N | 25 mm, 10 mm | #8, #3 |          |       | 35 mm | 81mm  |
| EL2516A12N | 25 mm, 16 mm | #8, #5 | 25M, 15M |       | 35 mm | 86mm  |
| EL2518A12N | 25 mm, 18 mm |        |          |       | 35 mm | 90mm  |
| EL2522A12N | 25 mm, 22 mm | #8, #7 |          |       | 35 mm | 100mm |
| EL2520A12N | 25 mm, 20 mm | #8, #6 | 25M, 20M |       | 35 mm | 98mm  |
| EL2814A12N | 28 mm, 14 mm |        |          |       | 40 mm | 86mm  |
| EL2816A12N | 28 mm, 16 mm | #9, #5 | 30M, 15M |       | 40 mm | 88mm  |
| EL2818A12N | 28 mm, 18 mm |        |          |       | 40 mm | 93mm  |
| EL3016A12N | 30 mm, 16 mm |        |          |       | 40 mm | 99mm  |
| EL2825A12N | 28 mm, 25 mm | #9, #8 | 30M, 25M |       | 40 mm | 104mm |
| EL3028A12N | 30 mm, 28 mm |        |          |       | 40 mm | 117mm |
| EL2820A12N | 28 mm, 20 mm | #9, #6 | 30M, 20M |       | 40 mm | 101mm |
| EL3018A12N | 30 mm, 18 mm |        |          |       | 40 mm | 103mm |
| EL2822A12N | 28 mm, 22 mm | #9, #7 |          |       | 40 mm | 103mm |
| EL3025A12N | 30 mm, 25 mm |        |          |       | 40 mm | 115mm |

|            |              |          |  |  |       |       |
|------------|--------------|----------|--|--|-------|-------|
| EL3022A12N | 30 mm, 22 mm |          |  |  | 40 mm | 113mm |
| EL3020A12N | 30 mm, 20 mm |          |  |  | 40 mm | 110mm |
| EL3216A12N | 32 mm, 16 mm | #10, #5  |  |  | 45 mm | 92mm  |
| EL3218A12N | 32 mm, 18 mm |          |  |  | 45 mm | 98mm  |
| EL3228A12N | 32 mm, 28 mm | #10, #9  |  |  | 45 mm | 110mm |
| EL4038A12N | 40 mm, 38 mm |          |  |  | 55 mm | 133mm |
| EL3432A12N | 34 mm, 32 mm |          |  |  | 50 mm | 123mm |
| EL3836A12N | 38 mm, 36 mm | #12, #11 |  |  | 55 mm | 128mm |
| EL3632A12N | 36 mm, 32 mm | #11, #10 |  |  | 50 mm | 120mm |
| EL4036A12N | 40 mm, 36 mm |          |  |  | 55 mm | 132mm |
| EL3634A12N | 36 mm, 34 mm |          |  |  | 50 mm | 130mm |
| EL3225A12N | 32 mm, 25 mm | #10, #8  |  |  | 45 mm | 109mm |
| EL3832A12N | 38 mm, 32 mm |          |  |  | 55 mm | 122mm |
| EL3428A12N | 34 mm, 28 mm |          |  |  | 50 mm | 120mm |
| EL3230A12N | 32 mm, 30 mm |          |  |  | 45 mm | 120mm |
| EL3220A12N | 32 mm, 20 mm | #10, #6  |  |  | 45 mm | 105mm |
| EL3430A12N | 34 mm, 30 mm |          |  |  | 50 mm | 131mm |
| EL3834A12N | 38 mm, 34 mm |          |  |  | 55 mm | 132mm |
| EL4034A12N | 40 mm, 34 mm |          |  |  | 55 mm | 136mm |

|             |              |          |          |  |       |       |
|-------------|--------------|----------|----------|--|-------|-------|
| EL4032A12N  | 40 mm, 32 mm |          |          |  | 55 mm | 126mm |
| EL3222A12N  | 32 mm, 22 mm | #10, #7  |          |  | 45 mm | 107mm |
| EL3630A12N  | 36 mm, 30 mm |          |          |  | 50 mm | 128mm |
| EL3628A12N  | 36 mm, 28 mm | #11, #9  | 35M, 30M |  | 50 mm | 118mm |
| EL3828A12N  | 38 mm, 28 mm | #12, #9  |          |  | 55 mm | 119mm |
| EL3425A12N  | 34 mm, 25 mm |          |          |  | 50 mm | 119mm |
| EL4028A12N  | 40 mm, 28 mm |          |          |  | 55 mm | 123mm |
| EL3625A12N  | 36 mm, 25 mm | #11, #8  | 35M, 25M |  | 50 mm | 116mm |
| EL3830A12N  | 38 mm, 30 mm |          |          |  | 55 mm | 130mm |
| EL4030A12N  | 40 mm, 30 mm |          |          |  | 55 mm | 134mm |
| EL4025A12N  | 40 mm, 25 mm |          |          |  | 55 mm | 122mm |
| EL3422A12N  | 34 mm, 22 mm |          |          |  | 50 mm | 117mm |
| EL3825A12N  | 38 mm, 25 mm | #12, #8  |          |  | 55 mm | 118mm |
| EL3622A12N  | 36 mm, 22 mm | #11, #7  |          |  | 50 mm | 114mm |
| EL3420A12N  | 34 mm, 20 mm |          |          |  | 50 mm | 115mm |
| EL3620A12N  | 36 mm, 20 mm | #11, #6  | 35M, 20M |  | 50 mm | 112mm |
| EL50T36A12N | 50 mm, 36 mm |          |          |  | 70 mm | 153mm |
| EL43T36A12N | 43 mm, 36 mm | #14, #11 | 45M, 35M |  | 60 mm | 148mm |
| EL50T40A12N | 50 mm, 40 mm |          |          |  | 70 mm | 157mm |

|              |              |          |          |  |       |       |
|--------------|--------------|----------|----------|--|-------|-------|
| EL50T38A12N  | 50 mm, 38 mm |          |          |  | 70 mm | 154mm |
| EL50T32A12N  | 50 mm, 32 mm |          |          |  | 70 mm | 147mm |
| EL50T34A12N  | 50 mm, 34 mm |          |          |  | 70 mm | 156mm |
| EL57T43TA12N | 57 mm, 43 mm | #18, #14 | 55M, 45M |  | 80 mm | 184mm |

Table 2/2

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                                                          |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------------------------------------|
| EL1210A12N       | 19mm              | 18mm              | 18mm         | 0.08 kg     | 285               | DIBt, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific, ITB                                                     |
| EL1614A12N       | 24mm              | 21mm              | 19mm         | 0.14 kg     | 150               | CARES, Kontrollrådet, RISE, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB, DIBt, KOMO                         |
| EL1412A12N       | 21mm              | 19mm              | 17mm         | 0.14 kg     | 150               | RISE, DIBt, Kontrollrådet, Kontrollrådet, nVent LENTON EPD - Product Specific, CARES, KOMO, ITB                         |
| EL1612A12N       | 24mm              | 19mm              | 18mm         | 0.14 kg     | 150               | LA City Approval, ITB, Kontrollrådet, Kontrollrådet, IAPMO®-UES, CARES, RISE, nVent LENTON EPD - Product Specific, KOMO |
| EL1410A12N       | 21mm              | 18mm              | 18mm         | 0.15 kg     | 150               | ITB, nVent LENTON EPD - Product Specific, Kontrollrådet                                                                 |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                            |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------|
| EL1610A12N       | 24mm              | 18mm              | 19mm         | 0.15 kg     | 150               | Kontrollrådet, ITB, nVent LENTON EPD - Product Specific                                   |
| EL1812A12N       | 29mm              | 19mm              | 18mm         | 0.25 kg     | 70                | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL1816A12N       | 29mm              | 24mm              | 18mm         | 0.25 kg     | 70                | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL1810A12N       | 29mm              | 18mm              | 19mm         | 0.25 kg     | 70                | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL1814A12N       | 29mm              | 21mm              | 19mm         | 0.25 kg     | 70                | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2012A12N       | 35mm              | 19mm              | 20mm         | 0.26 kg     | 70                | ITB, nVent LENTON EPD - Product Specific, KOMO, Kontrollrådet, CARES, RISE, Kontrollrådet |
| EL2014A12N       | 35mm              | 21mm              | 21mm         | 0.27 kg     | 70                | CARES, RISE, Kontrollrådet, KOMO, nVent LENTON EPD - Product Specific, ITB, Kontrollrådet |
| EL2010A12N       | 35mm              | 18mm              | 21mm         | 0.27 kg     | 70                | Kontrollrådet, ITB, nVent LENTON EPD - Product Specific                                   |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                                                                |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------------------------------------------|
| EL2016A12N       | 35mm              | 24mm              | 21mm         | 0.27 kg     | 70                | DIBt, LA City Approval, ITB, IAPMO®-UES, KOMO, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific, Kontrollrådet, CARES |
| EL2018A12N       | 35mm              | 29mm              | 21mm         | 0.27 kg     | 70                | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2212A12N       | 37mm              | 19mm              | 21mm         | 0.34 kg     | 50                | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2216A12N       | 37mm              | 24mm              | 22mm         | 0.35 kg     | 50                | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2210A12N       | 37mm              | 18mm              | 22mm         | 0.35 kg     | 50                | ITB, nVent LENTON EPD - Product Specific                                                                                      |
| EL2214A12N       | 37mm              | 21mm              | 22mm         | 0.35 kg     | 50                | ITB, nVent LENTON EPD - Product Specific                                                                                      |
| EL2218A12N       | 37mm              | 29mm              | 21mm         | 0.36 kg     | 50                | nVent LENTON EPD - Product Specific, ITB                                                                                      |
| EL2220A12N       | 37mm              | 35mm              | 23mm         | 0.38 kg     | 50                | nVent LENTON EPD - Product Specific, LA City Approval, IAPMO®-UES, ITB                                                        |
| EL2512A12N       | 40mm              | 19mm              | 22mm         | 0.43 kg     | 50                | Kontrollrådet, KOMO, CARES, Kontrollrådet, nVent LENTON EPD - Product Specific, ITB, RISE                                     |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                                  |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------------|
| EL2514A12N       | 40mm              | 21mm              | 22mm         | 0.44 kg     | 50                | CARES, RISE, ITB, Kontrollrådet, nVent LENTON EPD - Product Specific, KOMO, Kontrollrådet       |
| EL2510A12N       | 40mm              | 18mm              | 23mm         | 0.44 kg     | 50                | nVent LENTON EPD - Product Specific, Kontrollrådet                                              |
| EL2516A12N       | 40mm              | 24mm              | 22mm         | 0.45 kg     | 50                | CARES, ITB, KOMO, Kontrollrådet, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific       |
| EL2518A12N       | 40mm              | 29mm              | 21mm         | 0.47 kg     | 50                | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2522A12N       | 40mm              | 37mm              | 23mm         | 0.49 kg     | 50                | IAPMO®-UES, LA City Approval, nVent LENTON EPD - Product Specific, ITB                          |
| EL2520A12N       | 40mm              | 35mm              | 23mm         | 0.5 kg      | 50                | RISE, Kontrollrådet, DIBt, Kontrollrådet, CARES, nVent LENTON EPD - Product Specific, KOMO, ITB |
| EL2814A12N       | 42mm              | 21mm              | 23mm         | 0.61 kg     | 38                | KOMO, nVent LENTON EPD - Product Specific, ITB                                                  |
| EL2816A12N       | 42mm              | 24mm              | 22mm         | 0.62 kg     | 38                | nVent LENTON EPD - Product Specific, ITB, KOMO                                                  |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                            |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------|
| EL2818A12N       | 42mm              | 29mm              | 22mm         | 0.65 kg     | 38                | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL3016A12N       | 52mm              | 24mm              | 23mm         | 0.66 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL2825A12N       | 42mm              | 40mm              | 22mm         | 0.67 kg     | 38                | KOMO, ITB, IAPMO®-UES, nVent LENTON EPD - Product Specific, LA City Approval, DIBt        |
| EL3028A12N       | 52mm              | 42mm              | 23mm         | 0.68 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL2820A12N       | 42mm              | 35mm              | 24mm         | 0.69 kg     | 38                | nVent LENTON EPD - Product Specific, KOMO, ITB                                            |
| EL3018A12N       | 52mm              | 29mm              | 22mm         | 0.69 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL2822A12N       | 42mm              | 37mm              | 24mm         | 0.69 kg     | 38                | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL3025A12N       | 52mm              | 40mm              | 23mm         | 0.71 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL3022A12N       | 52mm              | 37mm              | 24mm         | 0.73 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL3020A12N       | 52mm              | 35mm              | 23mm         | 0.73 kg     | 34                | nVent LENTON EPD - Product Specific                                                       |
| EL3216A12N       | 45mm              | 24mm              | 23mm         | 0.81 kg     | 16                | CARES, Kontrollrådet, KOMO, RISE, Kontrollrådet, ITB, nVent LENTON EPD - Product Specific |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                            |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------|
| EL3218A12N       | 45mm              | 29mm              | 24mm         | 0.86 kg     | 16                | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL3228A12N       | 45mm              | 42mm              | 23mm         | 0.88 kg     | 16                | ITB, LA City Approval, IAPMO®-UES, DIBt, KOMO, nVent LENTON EPD - Product Specific        |
| EL4038A12N       | 57mm              | 53mm              | 23mm         | 1.47 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL3432A12N       | 55mm              | 45mm              | 23mm         | 1.24 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3836A12N       | 53mm              | 52mm              | 23mm         | 1.51 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL3632A12N       | 52mm              | 45mm              | 23mm         | 1.15 kg     | 16                | nVent LENTON EPD - Product Specific, IAPMO®-UES, LA City Approval                         |
| EL4036A12N       | 57mm              | 52mm              | 23mm         | 1.5 kg      | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL3634A12N       | 52mm              | 55mm              | 23mm         | 1.23 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3225A12N       | 45mm              | 40mm              | 24mm         | 0.91 kg     | 16                | Kontrollrådet, Kontrollrådet, CARES, ITB, KOMO, RISE, nVent LENTON EPD - Product Specific |
| EL3832A12N       | 53mm              | 45mm              | 24mm         | 1.51 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL3428A12N       | 55mm              | 42mm              | 23mm         | 1.28 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                                            |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------------------------------|
| EL3230A12N       | 45mm              | 52mm              | 23mm         | 0.95 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3220A12N       | 45mm              | 35mm              | 25mm         | 0.92 kg     | 16                | RISE, Kontrollrådet, Kontrollrådet, CARES, ITB, nVent LENTON EPD - Product Specific, KOMO |
| EL3430A12N       | 55mm              | 52mm              | 24mm         | 1.37 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3834A12N       | 53mm              | 55mm              | 24mm         | 1.62 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL4034A12N       | 57mm              | 55mm              | 24mm         | 1.61 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL4032A12N       | 57mm              | 45mm              | 24mm         | 1.5 kg      | 12                | nVent LENTON EPD - Product Specific, DIBt, ITB, CARES, RISE, Kontrollrådet                |
| EL3222A12N       | 45mm              | 37mm              | 25mm         | 0.93 kg     | 16                | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL3630A12N       | 52mm              | 52mm              | 24mm         | 1.28 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3628A12N       | 52mm              | 42mm              | 24mm         | 1.19 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL3828A12N       | 53mm              | 42mm              | 24mm         | 1.54 kg     | 12                | nVent LENTON EPD - Product Specific                                                       |
| EL3425A12N       | 55mm              | 40mm              | 24mm         | 1.31 kg     | 16                | nVent LENTON EPD - Product Specific                                                       |
| EL4028A12N       | 57mm              | 42mm              | 24mm         | 1.54 kg     | 12                | nVent LENTON EPD - Product Specific, ITB                                                  |

| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                       |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|----------------------------------------------------------------------|
| EL3625A12N       | 52mm              | 40mm              | 24mm         | 1.22 kg     | 16                | nVent LENTON EPD - Product Specific                                  |
| EL3830A12N       | 53mm              | 52mm              | 25mm         | 1.67 kg     | 12                | nVent LENTON EPD - Product Specific                                  |
| EL4030A12N       | 57mm              | 52mm              | 25mm         | 1.66 kg     | 12                | nVent LENTON EPD - Product Specific                                  |
| EL4025A12N       | 57mm              | 40mm              | 25mm         | 1.56 kg     | 100               | nVent LENTON EPD - Product Specific, CARES, RISE, ITB, Kontrollrådet |
| EL3422A12N       | 55mm              | 37mm              | 25mm         | 1.32 kg     | 16                | nVent LENTON EPD - Product Specific                                  |
| EL3825A12N       | 53mm              | 40mm              | 25mm         | 1.56 kg     | 12                | nVent LENTON EPD - Product Specific                                  |
| EL3622A12N       | 52mm              | 37mm              | 25mm         | 1.22 kg     | 16                | nVent LENTON EPD - Product Specific                                  |
| EL3420A12N       | 55mm              | 35mm              | 25mm         | 1.31 kg     | 16                | nVent LENTON EPD - Product Specific                                  |
| EL3620A12N       | 52mm              | 35mm              | 25mm         | 1.22 kg     | 16                | nVent LENTON EPD - Product Specific                                  |
| EL50T36A12N      | 70mm              | 52mm              | 31mm         | 3.08 kg     | 1                 | nVent LENTON EPD - Product Specific                                  |
| EL43T36A12N      | 66mm              | 52mm              | 30mm         | 2.1 kg      | 10                | LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific    |
| EL50T40A12N      | 70mm              | 57mm              | 30mm         | 3.09 kg     | 8                 | CARES, nVent LENTON EPD - Product Specific                           |


| Katalogové číslo | Bar Depth 1 (BD1) | Bar Depth 2 (BD2) | Bar Gap (BG) | Unit Weight | Množství v balení | Certifications                                                    |
|------------------|-------------------|-------------------|--------------|-------------|-------------------|-------------------------------------------------------------------|
| EL50T38A12N      | 70mm              | 53mm              | 31mm         | 3.06 kg     | 8                 | nVent LENTON EPD - Product Specific                               |
| EL50T32A12N      | 70mm              | 45mm              | 32mm         | 3 kg        | 8                 | CARES, nVent LENTON EPD - Product Specific                        |
| EL50T34A12N      | 70mm              | 55mm              | 31mm         | 3.22 kg     | 8                 | nVent LENTON EPD - Product Specific                               |
| EL57T43TA12N     | 83mm              | 66mm              | 35mm         | 4.87 kg     | 5                 | LA City Approval, IAPMO®-UES, nVent LENTON EPD - Product Specific |

**Designed to Meet:** AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

## DALŠÍ PODROBNOSTI O PRODUKTU

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

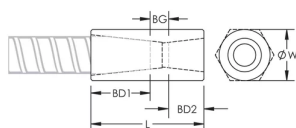

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**