

B-Series Vertical Filler Material Kit



B-Series vertical filler material kits contain the following: Filler material, vertical packing, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

VLASTNOSTI

Simplifies ordering

All components are for one-time use

SPECIFIKACE

Table 1/1

Katalogové číslo	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada
RBB1292B	38 mm	#12	
RBB14101B	43 mm	#14	45M
RBB1892B	57 mm	#18	55M
RBB592B	16 mm	#5	15M
RBB692B	20 mm	#6	20M
RBB792B	22 mm	#7	
RBB8101B	25 mm	#8	25M
RBB992B	28 mm	#9	30M

Katalogové číslo	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada
RBB1092B	32 mm	#10	
RBB11101B	36 mm	#11	35M

DALŠÍ PODROBNOSTI O PRODUKTU


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBB592B	RBF40	RBS35477	RBS5037	RBS5038
RBB692B	RBF40	RBS35477	RBS5037	RBS5038
RBB792B	RBF50	RBS35478	RBS5037	RBS5038
RBB8101B	RBF55	RBS354710	RBS5037	RBS5038
RBB992B	RBF80	RBS354711	RBS5037	RBS5038
RBB1092B	RBF90	RBS354712	RBS5037	RBS5038
RBB11101B	RBF105	RBS354712	RBS5037	RBS5038
RBB1292B	RBF125	RBS354715	RBS5037	RBS5038
RBB14101B	RBF180	RBS354715	RBS5037	RBS5039
RBB1892B	RBF220	RBS354720	RBS5037	RBS5039

DIAGRAMS

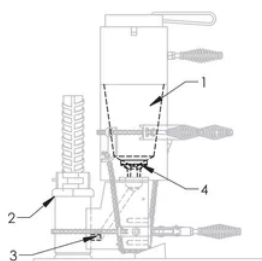

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná

instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE