

CFFP Tapered Plastic Screw-In Plug for A12, A22 and A32K Couplers



VLASTNOSTI

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFIKACE

Materiál: Polyetylen

Table 1/2

Katalogové číslo	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL28CFFP	156070	28 mm	#9	30M	59 mm	23 mm
EL12CFFP	156010	12 mm	#4	10M	59 mm	23 mm
EL25CFFP	156060	25 mm	#8	25M	59 mm	23 mm
EL20CFFP	156050	20 mm	#6	20M	59 mm	23 mm

Katalogové číslo	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL16CFFP	156030	16 mm	#5	15M	59 mm	23 mm
EL14CFFP	156020	14 mm			59 mm	23 mm


Table 2/2

Katalogové číslo	Article Number	Barva
EL28CFFP	156070	Black
EL12CFFP	156010	Red
EL25CFFP	156060	Red
EL20CFFP	156050	Yellow
EL16CFFP	156030	Black
EL14CFFP	156020	Green

DALŠÍ PODROBNOSTI O PRODUKTU

EL12CFFP and EL16CFFP can also be used on the A2 coupler families.

DIAGRAMS

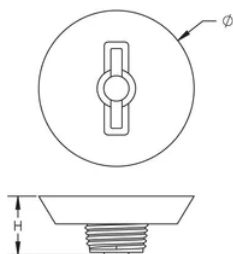

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE