


# Horizontal Pouring Basin, Side Fill

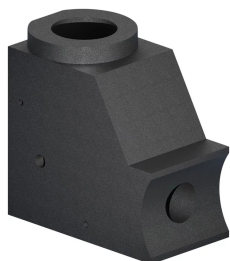

Side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve.

## VLASTNOSTI

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## SPECIFIKACE

**Materiál:** Graphite

Table 1/1

| Katalogové číslo | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|------------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBWS1547F        | 64 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |
| RBWS1547J        | 76 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |
| RBWS1547E        | 57 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |
| RBWS1547M        | 95 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |
| RBWS1547C        | 48 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |
| RBWS1547D        | 54 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |

| Katalogové číslo | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|------------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBWS1547X        | 38 mm        | 140 mm        | 22 mm         | 76 mm     | 137mm         | 67mm          |


## DALŠÍ PODROBNOSTI O PRODUKTU

RBWS1547 pouring basins require one RBW332 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

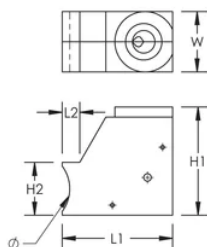

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE