


Air Terminal Base, Stamped Adjustable, Imperial Thread

Power Utilities

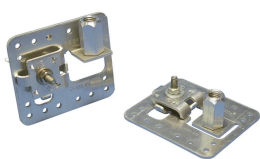

VLASTNOSTI

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping

SPECIFIKACE


Table 1/1

Katalogové číslo	Conductor Size, UL	Height (H)	Width (W)
LPA30212	Class 1 - Class 2 (4/0 Max)	34.92 mm	101.600 mm

DALŠÍ PODROBNOSTI O PRODUKTU

Vertical type bases are factory pre-configured for vertical mount applications.

DIAGRAMS

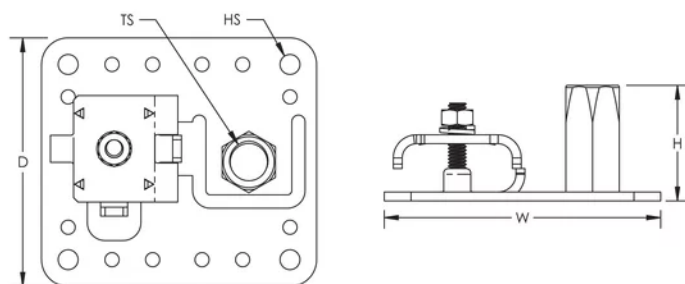

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRachte