


Assembly Parts for Rugged Components

Power Utilities

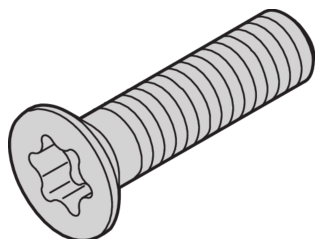

Assembly parts with thread-locking compound for rugged Side Panel, horizontal rail, cover plates, rear angle.

CERTIFICATIONS



VLASTNOSTI

Screws for the following fixings: Rugged side panel - horizontal rail, Rugged side panel - cover plate, Rugged side panel - rear angle

SPECIFIKACE

Table 1/2

Katalogové číslo	Typ	Length	Množství v balení	Thread Size	Materiál	Produktová řada
24566-105	Countersunk Screw	7 mm	100	M4	Stainless Steel	EuropacPRO
24566-104	Panhead Screw	8 mm	100	M4	Stainless Steel	EuropacPRO
24566-106	Countersunk Screw	10 mm	100	M4	Stainless Steel	EuropacPRO
24566-103	Panhead Screw	10 mm	100	M4	Stainless Steel	EuropacPRO

Katalogové číslo	Typ	Length	Množství v balení	Thread Size	Materiál	Produktová řada
24566-102	Panhead Screw	14 mm	100	M4	Stainless Steel	EuropacPRO
24566-101	Countersunk Screw	14 mm	100	M4	Stainless Steel	EuropacPRO
24566-100	Countersunk Screw	18 mm	100	M4	Stainless Steel	EuropacPRO
24560-140	Square Nut		100		Stainless Steel	EuropacPRO

Table 2/2

Katalogové číslo	Product Type	Works With
24566-105	Assembly Kit	Subracks
24566-104	Assembly Kit	Subracks
24566-106	Assembly Kit	Subracks
24566-103	Assembly Kit	Subracks
24566-102	Assembly Kit	Subracks
24566-101	Assembly Kit	Subracks
24566-100	Assembly Kit	Subracks
24560-140	Assembly Kit	Subracks

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE