


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

KATALOGOVÉ ČÍSLO

20848-617

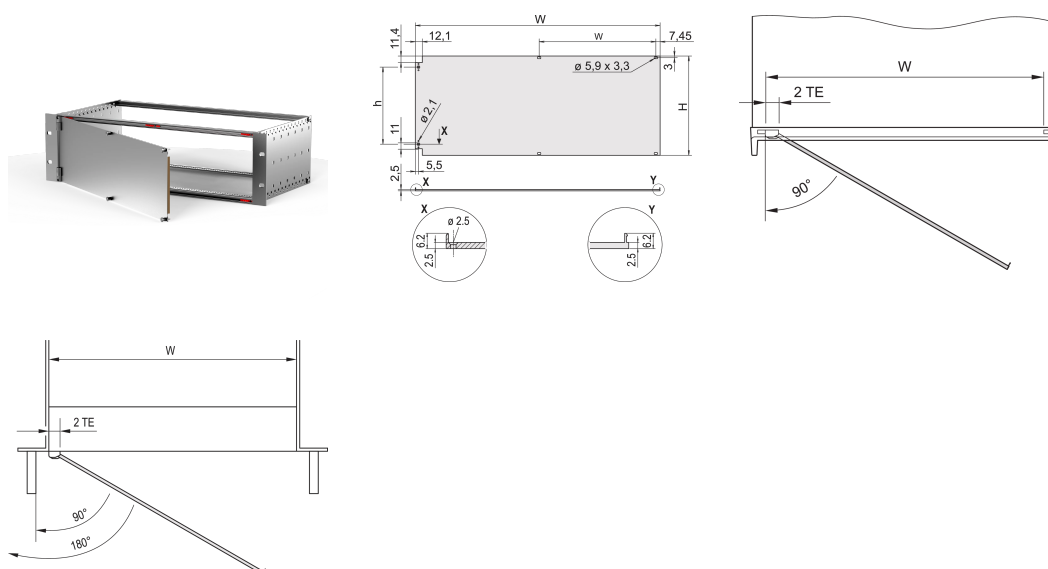

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICATIONS



VLASTNOSTI

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

VLASTNOSTI PRODUKTU

Product Type: Front Panel

Typ: Front Panel without Handle

Mounting: Hinged, Side

EMC Shielding: No (Retrofittable)

Gasket Type: Textile

Materiál: Hliník

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 6 U

Výška: 261.8 mm

Rack Width: 84 HP

Šířka: 426.4 mm

Množství v balení: 1

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE