


Front Panel, Front anodized, Rear Conductive, Unshielded, 3 U, 84 HP

Power Utilities

KATALOGOVÉ ČÍSLO

30838-123

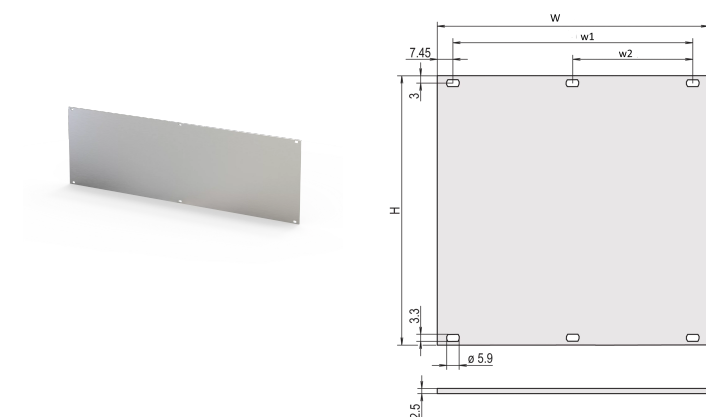

Front panel, unshielded, front anodized and rear conductive.

CERTIFICATIONS



VLASTNOSTI

Partial width front panel, Al, 2.5 mm

Al, front anodized, conductive

VLASTNOSTI PRODUKTU

Product Type: Front Panel

Typ: Front Panel without Handle

Typ rukojeti: None

Mounting: Screw-on Front

EMC Shielding: No

Materiál: Hliník

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3 U

Výška: 128.4 mm

Rack Width: 84 HP

Šířka: 426.4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Please order fixing material (sleeves, collar screws) separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte