


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

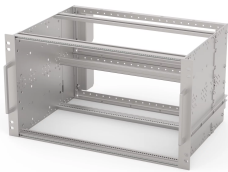

CERTIFICATIONS



VLASTNOSTI

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

SPECIFIKACE

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Hloubka	Množství v balení	For Mounting	Board Depth
21500-070	6 U	36 HP	320 mm	1	Backplane	220 mm
21500-067	3 U	36 HP	320 mm	1	Backplane	220 mm
21500-029	3 U	84 HP	320 mm	1	Backplane	220 mm
21500-027	6 U	84 HP	320 mm	1	Backplane	220 mm

Table 2/3

Katalogové číslo	Gasket Type	Shock and Vibration Tolerance	Rukojeť v ceně	Mounting	Complies With	EMC Shielding
21500-070	Textile	5 g (force)	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-067	Textile	5 g (force)	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-029	Textile	5 g (force)	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No
21500-027	Textile	5 g (force)	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No

Table 3/3

Katalogové číslo	Product Type	Static Load	Certifications
21500-070	Subrack/Chassis	15 kgf	RoHS
21500-067	Subrack/Chassis	15 kgf	RoHS
21500-029	Subrack/Chassis	15 kgf	RoHS, SNCF

Katalogové číslo	Product Type	Static Load	Certifications
21500-027	Subrack/Chassis	15 kgf	RoHS, SNCF

DALŠÍ PODROBNOSTI O PRODUKTU

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRachte