


EuropacPRO 19" Subrack Kit for Railway, Shielded, SNCF, CompactPCI

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, shielded version for CompactPCI applications.

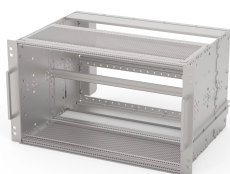

CERTIFICATIONS



VLASTNOSTI

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

SPECIFIKACE

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Množství v balení	For Mounting	Board Depth	Shock and Vibration Tolerance
21500-072	6 U	36 HP	1	Backplane	160 mm	5 g (force)
21500-069	3 U	36 HP	1	Backplane	160 mm	5 g (force)
21500-047	3 U	84 HP	1	Backplane	160 mm	5 g (force)
21500-046	6 U	84 HP	1	Backplane	160 mm	5 g (force)

Table 2/3

Katalogové číslo	Rukojeť v ceně	Mounting	Complies With	Hloubka	EMC Shielding	Product Type
21500-072	Yes	Rack	IEC 60297-3-103, IEEE 1101.10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Yes	Subrack/Chassis
21500-069	Yes	Rack	IEC 60297-3-103, IEEE 1101.10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Yes	Subrack/Chassis
21500-047	Yes	Rack	IEC 60297-3-103, IEEE 1101.10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Yes	Subrack/Chassis
21500-046	Yes	Rack	IEC 60297-3-103, IEEE 1101.10, SNCF NFF 61005, SNCF NFF 60002	320 mm	Yes	Subrack/Chassis

Table 3/3

Katalogové číslo	Static Load	Certifications
------------------	-------------	----------------

21500-072	15 kgf	RoHS
21500-069	15 kgf	RoHS
21500-047	15 kgf	RoHS, SNCF
21500-046	15 kgf	RoHS, SNCF

DALŠÍ PODROBNOSTI O PRODUKTU

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Version 9 T available on request; Test reports available online.

Guide rails color according to IEEE 1101.10 red = space for CPU-board; grey = space for peripheral boards; green = space for CompactPCI; 19"-power supplies 0,1" offset.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE