


EuropacPRO Rugged Rear Angle for Textile EMC Gasket

Power Utilities

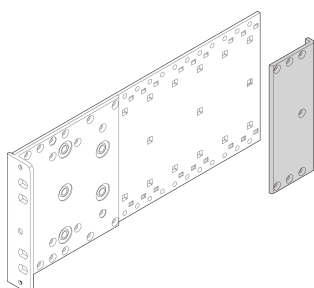

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

CERTIFICATIONS



VLASTNOSTI

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

SPECIFIKACE

Table 1/2

Katalogové číslo	Rack Height	Množství v balení	Výška	Produktová řada	Product Type	Typ
24566-499	6 U	1	265.9 mm	EuropacPRO	Cover	Rugged
24566-197	3 U	1	132.6 mm	EuropacPRO	Cover	Rugged

Katalogové číslo	Rack Height	Množství v balení	Výška	Produktová řada	Product Type	Typ
24566-199	3 U	1	132.6 mm	EuropacPRO	Cover	Rugged
24566-497	6 U	1	265.9 mm	EuropacPRO	Cover	Rugged

Table 2/2

Katalogové číslo	Works With	Balení	Certifications
24566-499	Subracks	Pair	RoHS
24566-197	Subracks	Pair	
24566-199	Subracks	Pair	RoHS
24566-497	Subracks	Pair	

DALŠÍ PODROBNOSTI O PRODUKTU

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE