


Front Panel, Shielded, Bottom Hinged

Power Utilities

U-profile front panel bottom hinged for textile gasket.

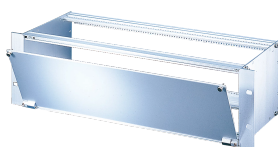

CERTIFICATIONS



VLASTNOSTI

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFIKACE

Table 1/3

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Gasket Type	Front Finish
20848-606	4 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-604	6 U	84 HP	1	Hinged, Bottom	Textile	Anodized

Katalogové číslo	Rack Height	Rack Width	Množství v balení	Mounting	Gasket Type	Front Finish
20848-608	3 U	28 HP	1	Hinged, Bottom	Textile	Anodized
20848-600	3 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-605	4 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-599	3 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-601	3 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-607	4 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-602	6 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-696	6 U	28 HP	1	Hinged, Bottom	Textile	Anodized
20848-603	6 U	63 HP	1	Hinged, Bottom	Textile	Anodized

Table 2/3

Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška	Materiál
20848-606	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Hliník
20848-604	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Hliník
20848-608	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Hliník
20848-600	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Hliník
20848-605	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Hliník
20848-599	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Hliník

Katalogové číslo	Rear Finish	Treated Edges	Complies With	EMC Shielding	Výška	Materiál
20848-601	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Hliník
20848-607	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Hliník
20848-602	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Hliník
20848-696	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Hliník
20848-603	Conductive	No	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Hliník

Table 3/3

Katalogové číslo	Product Type	Typ	Šířka
20848-606	Front Panel	Front Panel without Handle	319.7 mm
20848-604	Front Panel	Front Panel without Handle	426.4 mm
20848-608	Front Panel	Front Panel without Handle	141.9 mm
20848-600	Front Panel	Front Panel without Handle	319.7 mm
20848-605	Front Panel	Front Panel without Handle	213 mm
20848-599	Front Panel	Front Panel without Handle	213 mm
20848-601	Front Panel	Front Panel without Handle	426.4 mm
20848-607	Front Panel	Front Panel without Handle	426.4 mm
20848-602	Front Panel	Front Panel without Handle	213 mm
20848-696	Front Panel	Front Panel without Handle	141.9 mm

Katalogové číslo	Product Type	Typ	Šířka
20848-603	Front Panel	Front Panel without Handle	319.7 mm

DALŠÍ PODROBNOSTI O PRODUKTU

Front panel can be removed in opened position (> 135°).

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE