


LAN Surge Protector

Power Utilities

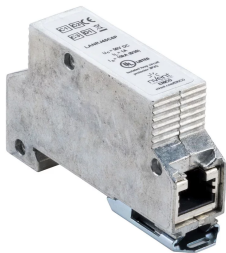

CERTIFICATIONS



VLASTNOSTI

Rugged, metallic enclosure provides both environmental and electrical shielding

Up to CAT6 and POE (Power Over Ethernet) protection in one product


Simple, bi-directional installation

SPECIFIKACE

Katalogové číslo	LANRJ45C6P
Nominal System Voltage (Un)	48 VDC
Max Continuous Operating Voltage (Uc)	50 VDC
Voltage Protection Rating (VPR), L-L	150 V
Voltage Protection Rating (VPR), L-PE	550 V
Nominal Discharge Current (In), L-L	150 A 8/20 µs
Impulse Current (Iimp)	1 kA 10/350 µs

Katalogové číslo	LANRJ45C6P
Rated Load Current (IL)	1 A
Frequency	250 MHz Max
Temperature	-40 to 80 °C
Enclosure Rating	IP 20
Height (H)	75 mm
Width (W)	19 mm

DIAGRAMS

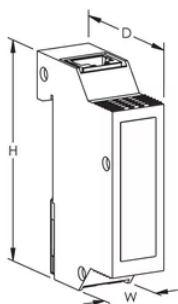

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE