


MultipacPRO 19" Chassis Basic Kit

Power Utilities

Such a kit enables a customer to configure the 3 different top / bottom covers.

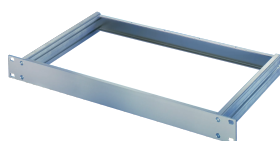

CERTIFICATIONS



VLASTNOSTI

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

SPECIFIKACE

Table 1/2

Katalogové číslo	Rack Height	Hloubka	Usable Width	Mounting	Complies With	EMC Shielding
20860-203	1 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-201	1 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Katalogové číslo	Rack Height	Hloubka	Usable Width	Mounting	Complies With	EMC Shielding
20860-204	1 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-202	1 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-205	1 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-211	2 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-212	2 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-210	2 U	220 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-214	2 U	460 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-213	2 U	400 mm	4 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-219	3 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-222	3 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-220	3 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-221	3 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-230	4 U	400 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-228	4 U	280 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-231	4 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-229	4 U	340 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)
20860-240	5 U	460 mm	403 mm	Rack	IEC 60297-3-100	No (Retrofittable)

Table 2/2

Katalogové číslo	Produktová řada	Product Type	Typ	Certifications
------------------	-----------------	--------------	-----	----------------

20860-203	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-201	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-204	MultipacPRO	Subrack/Chassis	Configurable	
20860-202	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-205	MultipacPRO	Subrack/Chassis	Configurable	
20860-211	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-212	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-210	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-214	MultipacPRO	Subrack/Chassis	Configurable	
20860-213	MultipacPRO	Subrack/Chassis	Configurable	
20860-219	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-222	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-220	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-221	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-230	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-228	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-231	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-229	MultipacPRO	Subrack/Chassis	Configurable	RoHS
20860-240	MultipacPRO	Subrack/Chassis	Configurable	RoHS

DALŠÍ PODROBNOSTI O PRODUKTU

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE