


Novastar Base/Plinth

Power Utilities

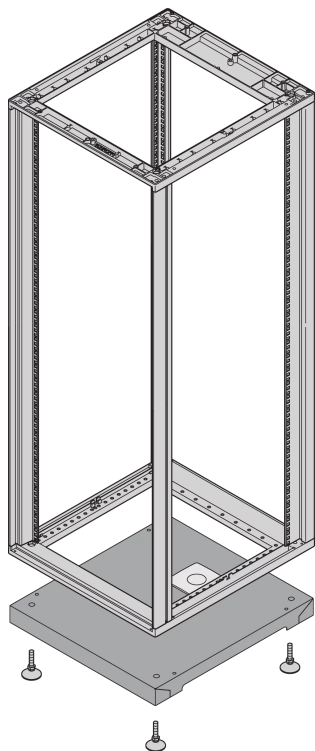

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

CERTIFICATIONS



VLASTNOSTI

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

SPECIFIKACE

Table 1/2

Katalogové číslo	Šířka	Hloubka	Barva	Kód barvy	Výška	Product Type
27230-076	900 mm	900 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-072	553 mm	800 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-080	1000 mm	1000 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-070	553 mm	500 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-071	553 mm	600 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base

Table 2/2

Katalogové číslo	Typ
27230-076	Base Plinth
27230-072	Base Plinth
27230-080	Base Plinth
27230-070	Base Plinth
27230-071	Base Plinth

DALŠÍ PODROBNOSTI O PRODUKTU

Please order brush strip separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE