

UFS nVent ERIFLEX Flexibar and IBSB Support Kit

Power Utilities



CERTIFICATIONS



VLASTNOSTI

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Conductor Thickness	Conductor Width	Height (H)	Width (W)	A
UFS-KIT	553590	2 – 8 mm	15.5 – 120.0 mm	57.50 mm	30 mm	24 mm


Table 2/2

Katalogové číslo	Article Number	B	Unit Weight
UFS-KIT	553590	15 mm	2.300 kg

DALŠÍ PODROBNOSTI O PRODUKTU

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

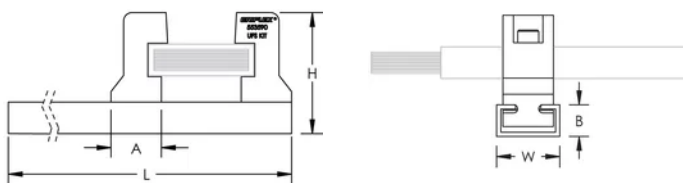

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE