

19" Front Panel With Holes for Handles



Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

CERTIFICATIONS



VLASTNOSTI

19" front panels have additional holes for mounting of handles

SPECIFIKACE

Rack Width:	95HP
Materiál:	Hliník
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Katalogové číslo	Rack Height	Hloubka (D)	Typ rukojeti	Povrchová úprava	Mounting	Množství v balení
30219-161	1U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-050	1U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-162	2U	3mm	Front Handle	Anodized	Screw-on Front	1

Katalogové číslo	Rack Height	Hloubka (D)	Typ rukojeti	Povrchová úprava	Mounting	Množství v balení
40304-051	2U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-163	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-164	4U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-052	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-165	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-053	4U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-166	6U		Front Handle	Anodized	Screw-on Front	1
40304-054	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-055	6U	3mm	Front Handle	Anodized	Screw-on Front	1


Table 2/3

Katalogové číslo	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Výška (H)	Typ
30219-161	Anodized	Anodized	No	No	43.6mm	19" Front Panel
40304-050	Anodized	Anodized	Yes	No	43.6mm	19" Front Panel
30219-162	Anodized	Anodized	No	No	88.1mm	19" Front Panel
40304-051	Anodized	Anodized	Yes	No	88.1mm	19" Front Panel
30219-163	Anodized	Anodized	No	No	132.5mm	19" Front Panel
30219-164	Anodized	Anodized	No	No	177mm	19" Front Panel
40304-052	Anodized	Anodized	Yes	No	132.5mm	19" Front Panel

Katalogové číslo	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Výška (H)	Typ
30219-165	Anodized	Anodized	No	No	221.4mm	19" Front Panel
40304-053	Anodized	Anodized	Yes	No	177mm	19" Front Panel
30219-166	Anodized	Anodized	No	No	265.9mm	19" Front Panel
40304-054	Anodized	Anodized	Yes	No	221.4mm	19" Front Panel
40304-055	Anodized	Anodized	Yes	No	265.9mm	19" Front Panel

Table 3/3

Katalogové číslo	Šířka (W)	Rychlé odeslání
30219-161	483mm	Ne
40304-050	483mm	Ne
30219-162	483mm	Ne
40304-051	483mm	Ne
30219-163	483mm	Ne
30219-164	483mm	Ne
40304-052	483mm	Ne
30219-165	483mm	Ne
40304-053	483mm	Ne
30219-166	483mm	Ne
40304-054	483mm	Ne
40304-055	483mm	Ne

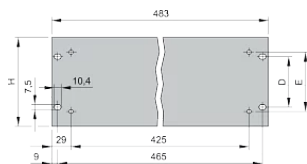

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE