

19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.



CERTIFICATIONS



VLASTNOSTI

Vented front panels (Aluminum) allows heat dissipation

SPECIFIKACE

Rack Width:	95HP
Materiál:	Hliník
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Katalogové číslo	Rack Height	Povrchová úprava	Mounting	Množství v balení	Front Finish	Rear Finish
30118-962	1U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized

Katalogové číslo	Rack Height	Povrchová úprava	Mounting	Množství v balení	Front Finish	Rear Finish
30702-056	1U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30118-964	3U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-058	3U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted

Table 2/3

Katalogové číslo	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ	Šířka (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm

Katalogové číslo	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ	Šířka (W)
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm


Table 3/3

Katalogové číslo	Rychlé odeslání
30118-962	Ne
30702-044	Ne
30702-047	Ne
30702-056	Ne
30118-963	Ne
30702-045	Ne
30702-048	Ne
30702-057	Ne
30118-964	Ne
30702-046	Ne
30702-049	Ne
30702-058	Ne

DALŠÍ PODROBNOSTI O PRODUKTU

Please order 19" assembly kit separately.

DIAGRAMS

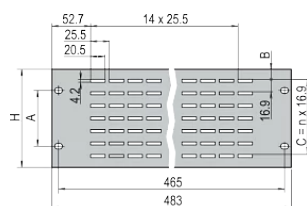

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE