


AMC Front Panel With Pull Handle

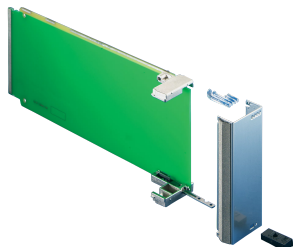

AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

CERTIFICATIONS



VLASTNOSTI

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

SPECIFIKACE

Accessory Type: Front panel

Product Type: Front Panel


Table 1/2

Katalogové číslo	Výška (H)	Rack Width	Design Feature	Materiál	Povrchová úprava	Množství v balení
30849-682	73.8mm	6HP	Full-Size	Hliník	Passivated	1
30849-670	148.8mm	4HP		Hliník	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Hliník	Passivated	1

Katalogové číslo	Výška (H)	Rack Width	Design Feature	Materiál	Povrchová úprava	Množství v balení
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-658	73.8mm	4HP	Mid-Size	Hliník	Passivated	1

Table 2/2

Katalogové číslo	Front Finish	Rear Finish	Hloubka (D)	Šířka (W)	Rychlé odeslání
30849-682	Raw	Raw	2.5mm	29mm	Ne
30849-670	Raw	Raw	2.5mm	19mm	Ne
30849-694	Raw	Raw	2.5mm	29mm	Ne
30849-403	Raw	Raw	1mm	19mm	Ne
30849-404	Raw	Raw	1mm	29mm	Ne
30849-406	Raw	Raw	1mm	19mm	Ne
30849-407	Raw	Raw	1mm	29mm	Ne
30849-402	Raw	Raw	1mm	13.9mm	Ne
30849-658	Raw	Raw	2.5mm	19mm	Ne

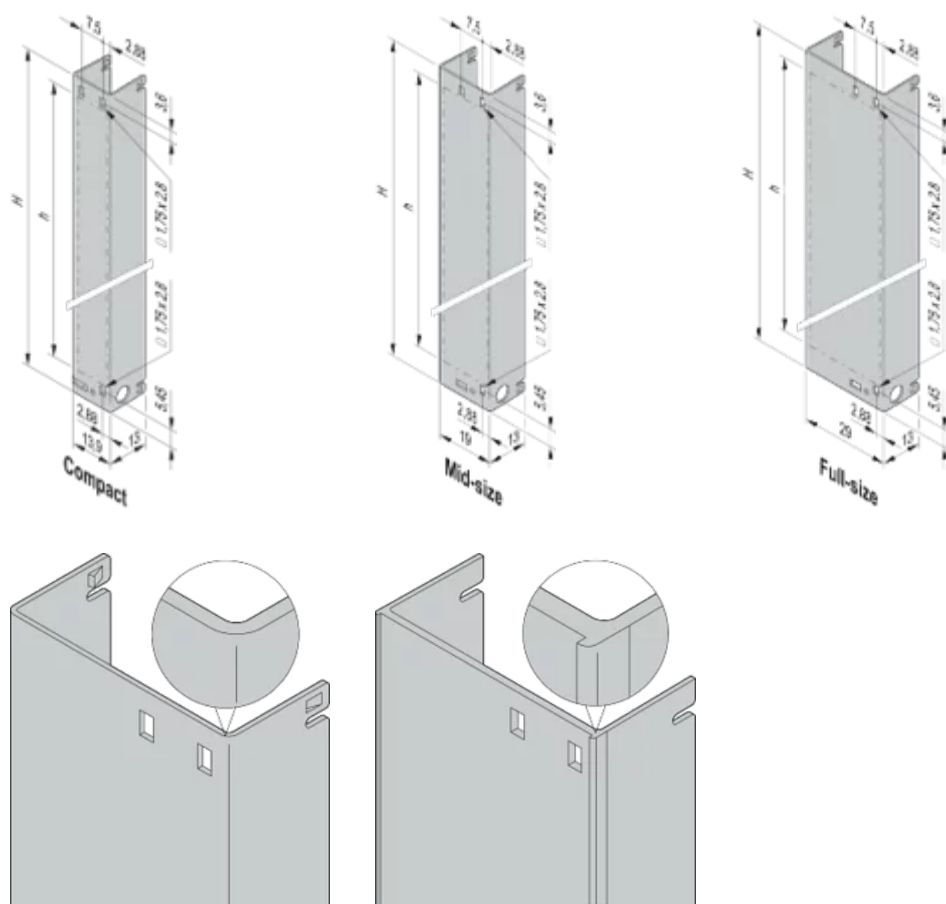

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE