


On Board Rack

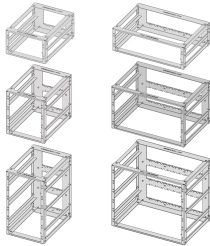

Suitable for ongoing vibrations, shock, high temperatures, and high humidity.

CERTIFICATIONS



VLASTNOSTI

For mobile railway applications

Suitable for ongoing vibrations, shock, high temperatures, and high humidity

Suitable for 1, 2, or 3 U SNCF subracks (NF F61-005, CF 60-002)

Rear side is equipped for standard connectors; crossbar can be custom-coded for the SNCF coding pins

Crossbar with integrated cable channel

Several racks can be stacked or fitted in rows

Produced using a welding process, certified to EN 15085 (CL2)

Stainless Steel welds passivated to prevent corrosion

SPECIFIKACE

Static Load:	25kg
Hloubka:	341.8mm
Product Type:	Rack
Complies With:	SNCF NFF 61005; SNCF NFF 60002
Frame Material:	Ocel

Table 1/2

Katalogové číslo	Rack Height	Výška	Rack Width	Šířka	Množství v balení	Materiál
10170-017	9U	423.4mm	36HP	252.65mm	1	Stainless Steel
10170-016	9U	423.4mm	84HP	496.4mm	1	Stainless Steel
10170-015	3U	156.7mm	36HP	252.65mm	1	Stainless Steel
10170-012	6U	290mm	84HP	496.4mm	1	Stainless Steel
10170-014	3U	156.7mm	84HP	496.4mm	1	Stainless Steel
10170-013	6U	290mm	36HP	252.65mm	1	Stainless Steel

Table 2/2

Katalogové číslo	Rychlé odeslání
10170-017	Ne
10170-016	Ne
10170-015	Ne
10170-012	Ne
10170-014	Ne
10170-013	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE