


Collar Screw, Cross Recess/Slotted

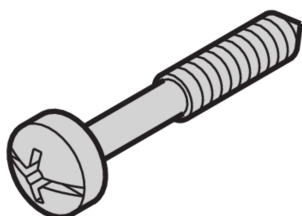

CERTIFICATIONS



SPECIFIKACE

Product Type: Screw

Typ: Screw

Table 1/3

Katalogové číslo	Diameter	Length	Materiál	Povrchová úprava	Množství v balení	Thread Size
21101-102		12.3mm	Ocel	Zinc Top Coat	100	M2.5
21101-906		12.3mm	Stainless Steel		100	M2.5
21101-323		11mm			100	M2.5
21102-026	2.5mm	12.3mm	Ocel	Nickel Plated	100	M2.5
21101-101		12.3mm	Ocel	Nickel Plated	100	M2.5

Table 2/3

Katalogové číslo	Hloubka	Výška	Šířka	Works With	Thread Type	Torque
21101-102	14.3mm	5mm	5mm	Front Panels	Metric	0.3N·m
21101-906				Front Panels		0.3N·m
21101-323				Front Panels		
21102-026				Frame Type Plug-In Unit, Cassettes		0.3N·m
21101-101	14.3mm	5mm	5mm	Front Panels	Metric	0.3N·m

Table 3/3

Katalogové číslo	Certifications	Rychlé odeslání
21101-102	RoHS	Ne
21101-906	RoHS	Ne
21101-323		Ne
21102-026		Ne
21101-101	RoHS	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE