


CompacPRO Front/Rear Panel, With Hidden Fixing

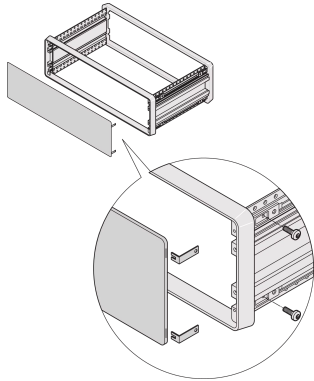

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

CERTIFICATIONS



VLASTNOSTI

Al panel, 2.5 mm

SPECIFIKACE

Material:	Hliník
Povrchová úprava:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Výška	Rack Width	Šířka	Množství v balení	Front Finish
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized

Katalogové číslo	Rack Height	Výška	Rack Width	Šířka	Množství v balení	Front Finish
24575-035	2U	84mm	42HP	238.7mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized

Table 2/2

Katalogové číslo	Rear Finish	Treated Edges	Hloubka	Rychlé odeslání
24575-115	Anodized	No	2.5mm	Ne
24575-035	Anodized	No	2.5mm	Ne
24575-135	Anodized	No	2.5mm	Ne
24575-075	Anodized	No	2.5mm	Ne
24575-235	Anodized	No	2.5mm	Ne
24575-155	Anodized	No	2.5mm	Ne
24575-175	Anodized	No	2.5mm	Ne

Katalogové číslo	Rear Finish	Treated Edges	Hloubka	Rychlé odeslání
24575-255	Anodized	No	2.5mm	Ne
24575-275	Anodized	No	2.5mm	Ne
24575-455	Anodized	No	2.5mm	Ne
24575-475	Anodized	No	2.5mm	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE