


CPCI Backplane, System Slot Left

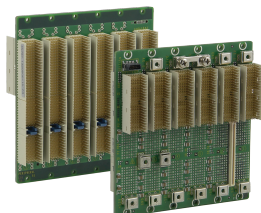

The nVent SCHROFF CompactPCI Backplanes have best in class signal integrity and MTBF values due to SMD components, ceramics capacitors and press fit connectors.

CERTIFICATIONS



VLASTNOSTI

In accordance with: PICMG 2.0 R3.0 CompactPCI Core specification, PICMG 2.1 R2.0 Hot Swap specification, PICMG 2.9 R1.0 System Management Bus specification, PICMG 2.10 R1.0 Keying specification

Digital GND can be connected to/isolated from chassis-GND by means of screws

V(I/O) adjustable to +3.3 V or +5 V

Infeed of supply voltages via powerbugs (ring tag M4), FASTONs

Outer layers act as GND surfaces

Utility plug for status signals (SMCQ)

Multiple backplanes can be placed together without loss of slots

Outstanding high-frequency noise suppression and very high MTBF values due to ceramic capacitors

Intelligent platform management bus (IPMB) connector to PICMG 2.9

SPECIFIKACE

Table 1/3

Katalogové číslo	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
------------------	--------------	-----------------	-------------	----------------	-------------	------------

23006-405	Backplane	5	3U	CompactPCI, 32-bit	Left	4HP
23006-406	Backplane	6	3U	CompactPCI, 32-bit	Left	4HP
23006-408	Backplane	8	3U	CompactPCI, 32-bit	Left	4HP
23006-422	Backplane	2	3U	CompactPCI, 64-bit	Left	4HP
23006-423	Backplane	3	3U	CompactPCI, 64-bit	Left	4HP
23006-424	Backplane	4	3U	CompactPCI, 64-bit	Left	4HP
23006-428	Backplane	8	3U	CompactPCI, 64-bit	Left	4HP
23006-443	Backplane	3	6U	CompactPCI, 64-bit	Left	4HP
23006-444	Backplane	4	6U	CompactPCI, 64-bit	Left	4HP
23006-445	Backplane	5	6U	CompactPCI, 64-bit	Left	4HP
23006-448	Backplane	8	6U	CompactPCI, 64-bit	Left	4HP
23006-714	Backplane	4	3U	CompactPCI, 32-bit	Left	4HP
23006-715	Backplane	5	3U	CompactPCI, 32-bit	Left	4HP
23006-716	Backplane	6	3U	CompactPCI, 32-bit	Left	4HP
23006-718	Backplane	8	3U	CompactPCI, 32-bit	Left	4HP
23006-732	Backplane	2	3U	CompactPCI, 64-bit	Left	4HP
23006-733	Backplane	3	3U	CompactPCI, 64-bit	Left	4HP
23006-734	Backplane	4	3U	CompactPCI, 64-bit	Left	4HP
23006-738	Backplane	8	3U	CompactPCI, 64-bit	Left	4HP

23006-763	Backplane	3	6U	CompactPCI, 64-bit	Left	4HP
23006-764	Backplane	4	6U	CompactPCI, 64-bit	Left	4HP
23006-765	Backplane	5	6U	CompactPCI, 64-bit	Left	4HP
23006-768	Backplane	8	6U	CompactPCI, 64-bit	Left	4HP

Table 2/3

Katalogové číslo	Voltage I/O	Connector Type	Power Connector Type	Utility Connector Type	Šířka	Množství v balení
23006-405	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.6mm	1
23006-406	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121mm	1
23006-408	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-422	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-423	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60mm	1
23006-424	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-428	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-443	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60mm	1
23006-444	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-445	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-448	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-714	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin		1
23006-715	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.6mm	1

Katalogové číslo	Voltage I/O	ConnectorType	Power ConnectorType	Utility ConnectorType	Šířka	Množství v balení
23006-716	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121mm	1
23006-718	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-732	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-733	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-734	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-738	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-763	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.6mm	1
23006-764	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-765	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-768	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1

Table 3/3

Katalogové číslo	Certifications	Rychlé odeslání
23006-405	RoHS, PICMG	Ne
23006-406	PICMG, RoHS	Ne
23006-408	RoHS, PICMG	Ne
23006-422	PICMG, RoHS	Ne
23006-423	RoHS	Ne
23006-424	RoHS, PICMG	Ne
23006-428	PICMG, RoHS	Ne

Katalogové číslo	Certifications	Rychlé odeslání
23006-443	RoHS, PICMG	Ne
23006-444	PICMG, RoHS	Ne
23006-445	RoHS, PICMG	Ne
23006-448	PICMG, RoHS	Ne
23006-714	RoHS, PICMG	Ne
23006-715	PICMG, RoHS	Ne
23006-716	RoHS, PICMG	Ne
23006-718	PICMG, RoHS	Ne
23006-732	RoHS, PICMG	Ne
23006-733	PICMG, RoHS	Ne
23006-734	RoHS, PICMG	Ne
23006-738	PICMG, RoHS	Ne
23006-763	RoHS, PICMG	Ne
23006-764	PICMG, RoHS	Ne
23006-765	RoHS, PICMG	Ne
23006-768	PICMG, RoHS	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE