


CPCI Power Backplane With P 47 Connector

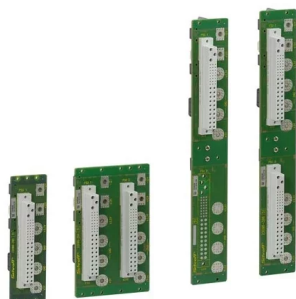

Power Backplane for CompactPCI Applications. With P47 Power Connector.

CERTIFICATIONS



VLASTNOSTI

In accordance with: PICMG 2.11 R1.0 CompactPCI Power Interface specification

In accordance with: PICMG 2.9 R1.0 System Management Bus specification

Single, parallel or redundant operation possible

Geographical address adjustable

Power supply over crimp contacts inserted into the plug, no supply voltage on the backplane

Power cable available as an accessory

DC outlets with powerbugs for extremely low drops in voltage

SPECIFIKACE

Table 1/2

Katalogové číslo	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-393	Backplane	1	3U	CompactPCI Power Backplane with P47	8HP	

Katalogové číslo	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-394	Backplane	2	3U	CompactPCI Power Backplane with P47	8HP	P47
23098-395	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-396	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	

Table 2/2

Katalogové číslo	Power Connector Type	Utility Connector Type	Šířka	Množství v balení	Rychlé odeslání
23098-393	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Ne
23098-394	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	80.3mm	1	Ne
23098-395	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Ne
23098-396	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Ne

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE