


PSU 19" DC/DC Coolpower 100 W, Triple, CPDC 312

KATALOGOVÉ ČÍSLO

13103-016

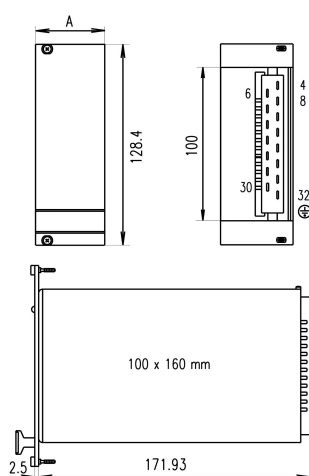

Pluggable 19" Power Supplies with H15 connector for fanless applications.

CERTIFICATIONS



VLASTNOSTI

Wide input voltage range from 20 to 72 VDC

Galvanic separation between primary and secondary circuits

High power density

External ON/OFF

VLASTNOSTI PRODUKTU

Product Type: Power Supply

Typ: 19" DC/DC Converter

Vstupní napětí DC: 20 – 72V

Power: 98W

Number of Output Voltages: 3

Voltage 1: 5V

Current 1: 10A

Voltage 2: 12V

Current 2: 2A

Voltage 3: 12V

Current 3: 2A

Rack Height: 3U

Rack Width: 6HP

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

For Input voltage 100-360 VDC see AC/DC Switched mode power supply.

Please order front panel separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE