


Plug-In Unit Microswitch for XL Handle With Cable and Plug

KATALOGOVÉ ČÍSLO

20817-877

Micro Swicth for XL Front panel.

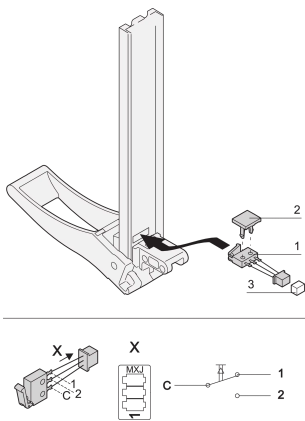

CERTIFICATIONS



VLASTNOSTI

Electr. life \geq 20,000 switching cycles

Plastic, PC, UL 94 V-0

Molex connector housing

Suitable mating connectors not included in scope of delivery

Mech. life \geq 20,000 switching cycles

Operating range -25 °C to +70 °C

Micro switch for XL handle

Max. switched current 50 mA

Molex crimp contact and fixing clip

VLASTNOSTI PRODUKTU

Product Type: Switch

Works With: Front Panels

Množství v balení: 10

Hloubka: 35.59mm

Výška: 8.2mm

Materiál: Polybutylene Terephthalate

Šířka: 7.84mm

DALŠÍ PODROBNOSTI O PRODUKTU

Mating connector not included in delivery. Mating connectors from Molex e.g. 53261-0319, 53048-0310, 53047-0310, 53398-0319, 51047-0300.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE