


VME64x System, 8 U, 21 Slot, Open Frame PSU

KATALOGOVÉ ČÍSLO

20836-820

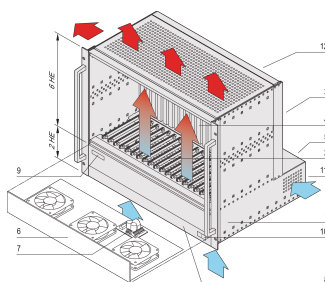

VME64 system for 21 VME64x boards 6 U, 160 mm. Rear I/O option The power for the system is supplied by a open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICATIONS



VLASTNOSTI

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 642 W (600 W at < 180 VAC)

Backplane VME64x 21 slot, 6 U, J1/J2 monolithic with P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 3 fans, cooling from bottom to top; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep, Rear I / O option

Display module for DC operating voltages, fan and temperature alarm

VLASTNOSTI PRODUKTU

Product Type: System

Number of Slots: 21

Typ: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Vstupní napětí AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 8U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: Yes

Complies With: ANSI/VITA 1.1-1997

Hloubka: 412mm

Výška: 354.8mm

Šířka: 449mm

Power: 600W

Net Weight: 19kg

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE