


PropacPRO Front Panel, Full Width, Unshielded, 2 U, 42 HP, 2 mm, Al, Anodized, Untreated Edges

KATALOGOVÉ ČÍSLO

20850-128

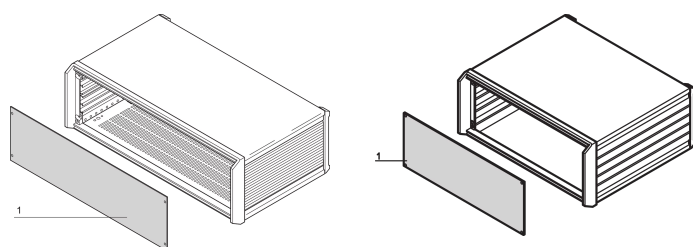

The front panel, full width for PropacPRO Case mounts to the frame of the case.

CERTIFICATIONS



VLASTNOSTI

Al panel, 2.0 mm (84 HP 2.5 mm)

VLASTNOSTI PRODUKTU

Rack Height: 2U

Rack Width: 42HP

Accessory Type: Front panel

Množství v balení: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: No

Hloubka: 2mm

Povrchová úprava: Anodized

Výška: 84mm

Materiál: Hliník

Product Type: Front Panel

Šířka: 238.7mm

Net Weight: 0.14kg

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE