


PSU Front Panel for Coolpower 100, Triple, 3 U, 6 HP, Shielded, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGOVÉ ČÍSLO

21006-957

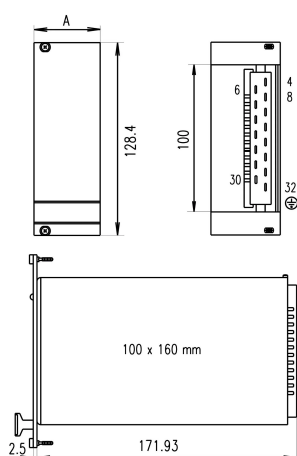

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

CERTIFICATIONS



VLASTNOSTI

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

VLASTNOSTI PRODUKTU

Product Type: Front Panel

Accessory Type: Front panel

Produktová řada: Coolpower

Materiál: Hliník

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3U

Výška: 128.4mm

Rack Width: 6HP

Šířka: 30.14mm

Hloubka: 2.5mm

Množství v balení: 1

Povrchová úprava: Anodized

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE