


HF Frame Type Plug-In Unit Slide Nut, M2.5; 100 pieces

KATALOGOVÉ ČÍSLO

21100-112

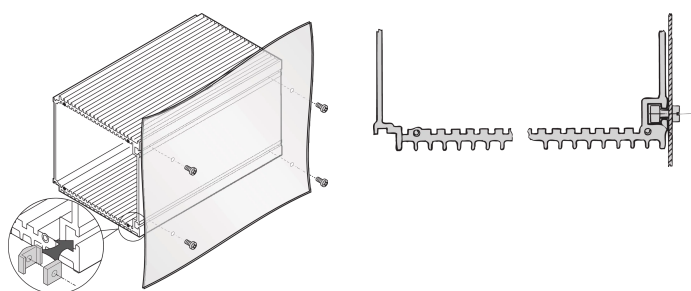

The slide nut can be inserted into the grooves of the HF tube and enable a user to assemble the tube.

CERTIFICATIONS



VLASTNOSTI

Alternative for threaded insert

VLASTNOSTI PRODUKTU

Množství v balení: 100

Hloubka (D): 5.5mm

Povrchová úprava: Pozinkovaná Ocel

Výška (H): 12mm

Materiál: Ocel; Polyamide 6

Product Type: Nut

Typ: Slide Nut

Šířka (W): 7mm


Works With: Frame Type Plug-In Unit

Net Weight: 0.079kg

Thread Size (TS): M2.5

Thread Type: Metric

DIAGRAMS

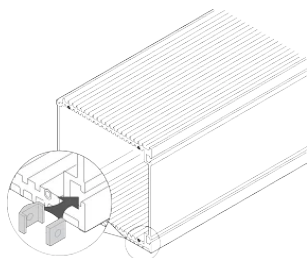

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE