


EuropacPRO 19" Subrack Kit for Power Distribution Module, Unshielded, 3 U, 84 HP, 115 mm

KATALOGOVÉ ČÍSLO

24563-100

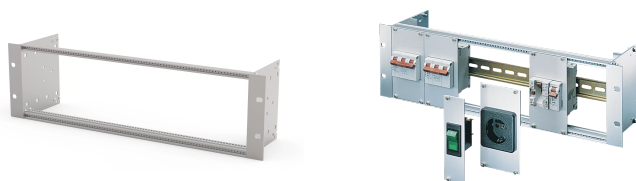

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted.

CERTIFICATIONS



VLASTNOSTI

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted

Modular frame to accept e.g. power distribution modules

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Aluminium side panels

Horizontal rails type "light"

VLASTNOSTI PRODUKTU

Product Type: Subrack/Chassis

Rack Height: 3U

Rack Width: 84HP

Hloubka: 115mm

For Mounting: Power Distribution Module

EMC Shielding: No

Static Load: 2.5kg

Rukojeť v ceně: No

Mounting: Rack

Complies With: IEC 60297-3-103

Množství v balení: 1

Povrchová úprava: Anodized; Passivated

Výška: 132.55mm

Materiál: Hliník

Net Weight: 0.64kg

Šířka: 482.6mm

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE