


Hood for 19" module support

KATALOGOVÉ ČÍSLO

24564-100

Hood to cover the rear side of 19" module support.

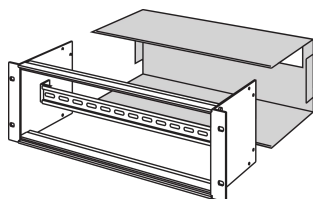

CERTIFICATIONS



VLASTNOSTI

For assembly at rear on 19" module supports

Rear cut out for cable entry (351 x 40mm) cover through two brush strips

Rear hood prepared for grounding kit

Brush strip (self-adhesive): Plastic PVC (RAL7032), Bristle: Nylon black

VLASTNOSTI PRODUKTU

Product Type: Cover

Produktová řada: EuropacPRO

Typ: Rear Hood

Works With: Subracks

Rack Height: 3U

Výška: 132.5mm

Rack Width: 84HP

Šířka: 431.5mm

Hloubka: 88.3mm

Materiál: Hliník

Množství v balení: 1

Net Weight: 0.83kg

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE