
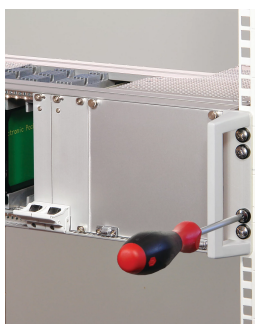


Front Handle, for Type R Side Panels

KATALOGOVÉ ČÍSLO

24566-010

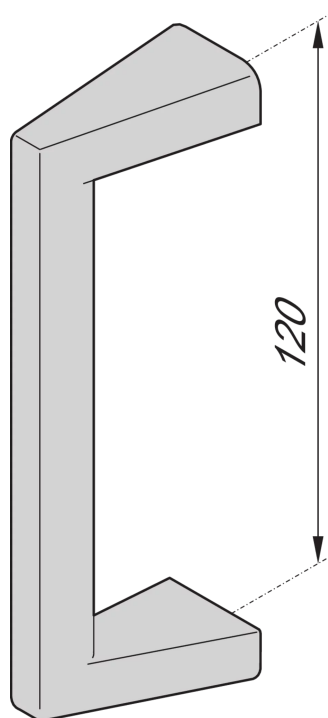

The front handle for a rugged subrack have a load-carrying capacity 30 kg. It optimizes the assembly of a subrack into a cabinet.

CERTIFICATIONS



VLASTNOSTI

Load-carrying capacity 30 kg

Suitable for 3 and 6 U side panels

The form of the handle make it much easier to assemble the M6 fixing screws

VLASTNOSTI PRODUKTU

Product Type: Handle

Works With: Subracks

Typ rukojeti: Straight

Šířka: 12.2mm

Materiál: Hliník

Barva: Silver

Množství v balení: 2

Hloubka: 40mm

Povrchová úprava: Strukturovaný Práškový

Net Weight: 0.154kg

Torque: 2.4N·m

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE