


CPCI System With PSB, 10 U, 14 Slot

KATALOGOVÉ ČÍSLO

24579-028

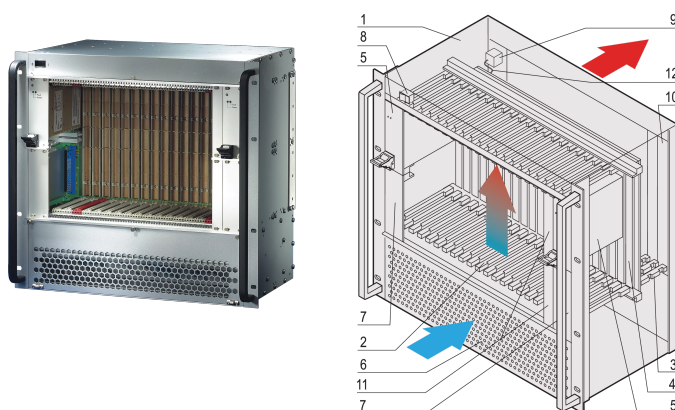

10 U CompactPCI System with PSB for fourteen 6 U Boards, fourteen RTM Boards and up to four 3U pluggable Power Supplies.

CERTIFICATIONS



VLASTNOSTI

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.16

System with vertical card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane, PSB (package switched backplane), PICMG 2.16 16-slot, 6 U, 64 bit (2 fabric/switch slots, 14 node slots)

Heat dissipation by fan module, from front to rear

Two 19" CompactPCI power supplies, 300 W (3 U, 8 HP), prepared for installation of two additional 19" compatible PSUs

Prepared for system monitoring with a chassis monitoring module (CMM)

VLASTNOSTI PRODUKTU

Product Type: System

Number of Slots: 16

Typ: 19" Rack Mount

Backplane Type: 6 U CompactPCI with PSB

Data Transfer: 64-bit PCI Bus; GbE

Power per Slot: 40W

Vstupní napětí AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 10U

Power Supply Type: (2) Pluggable AC PSU

Power Supply Included: Yes

Rear I/O: Yes

Complies With: PICMG 2.0 R3.0

Hloubka: 275mm

Výška: 443.7mm

Net Weight: 20kg

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE