


CPCI System for Pluggable PSU, Horizontal, 1 U, 2 Slot

KATALOGOVÉ ČÍSLO

24579-078

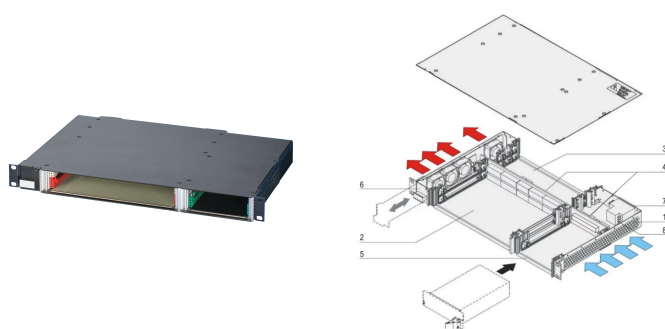

1 U CompactPCI System with horizontal Card Cage for two 6 U Boards, two RTM Boards and one CompactPCI 3 U Pluggable Power Supply.

CERTIFICATIONS



VLASTNOSTI

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 2 slot, 6 U, 64 bit, System slot left, Power connector (1 x P 47)

Heat dissipation by hot-swap fan unit (airflow right to left)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

VLASTNOSTI PRODUKTU

Product Type: System

Number of Slots: 2

Typ: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Vstupní napětí AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: No

Rear I/O: Yes

Complies With: PICMG 2.0 R3.0

Hloubka: 275mm

Výška: 44.64mm

Šířka: 449mm

Net Weight: 4.56kg

Množství v balení: 1

DALŠÍ PODROBNOSTI O PRODUKTU

Modified systems available on request.

48 VDC version on request.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE