


Varistar CP Top Cover Fan, Energy Efficient, Height 38 mm, 171 m³/h

KATALOGOVÉ ČÍSLO

24630-117

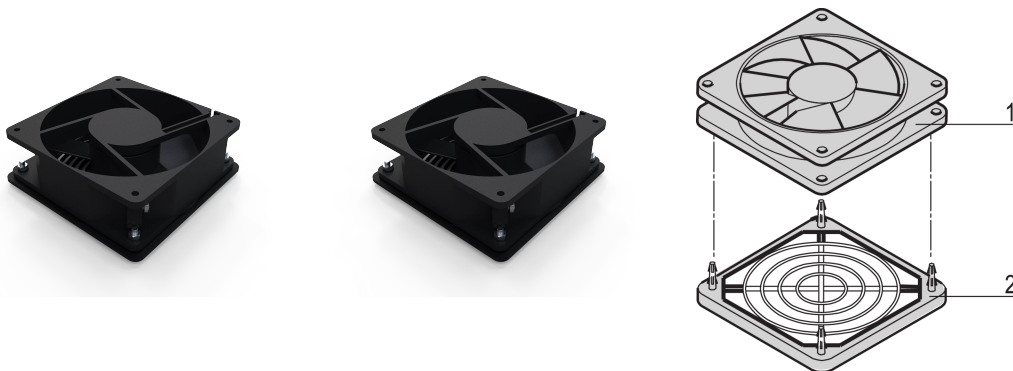

Top covers with fans are compact active cooling units which do not consume rack space. The Varistar fan for top cover comes with high specifications.

VLASTNOSTI

Varistar Top Cover Fan, Height 38 mm, 171 m³/h

VLASTNOSTI PRODUKTU

Product Type: Fan

Produktová řada: Varistar CP

Works With: Varistar CP

Hloubka: 119mm

Noise Level: 42.5dB(A)

Power: 9.6W

Max Static Pressure: 68.1Pa

Airflow @ 50 Hz: 171m³/h

Povrchová úprava: Strukturovaný Práškový

Výška: 38mm

Vstupní napětí AC: 18 – 27.6V

Materiál: Ocel

Množství v balení: 1

Šířka: 119mm

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE