


Eurorack Slide Rail, 40 kg, Depth-Adjustable

KATALOGOVÉ ČÍSLO

28127-001

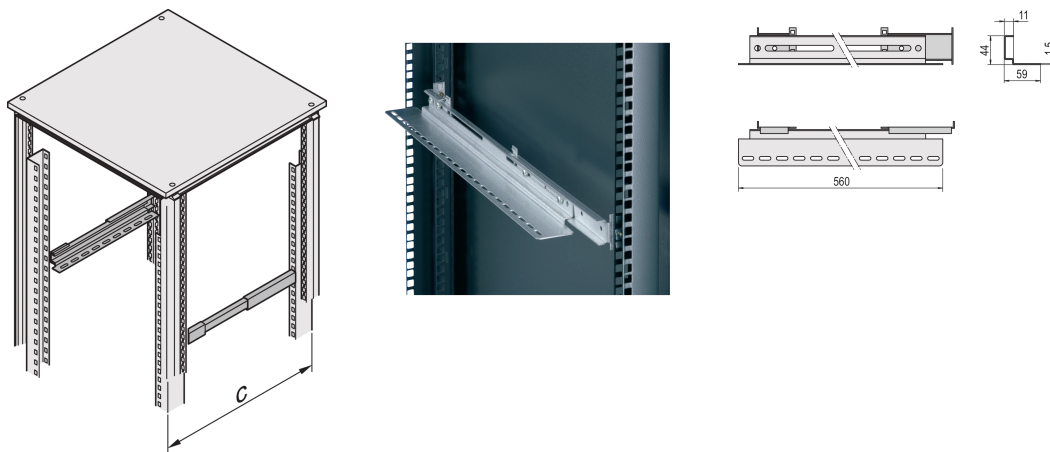

Eurorack Slide Rail with 40 kg load capacity for mounting on the cabinet uprights or 19" panel/slide mounts. The slide rail supports shelf of heavy 19" Chassis.

CERTIFICATIONS



VLASTNOSTI

Can be fitted in 1 U increments

Static load-carrying capacity 40 kg per pair, depth-adjustable

St, 1.5 mm, finish AlZn

For fitting to 19" panel/slide mounts or 19" server panel/slide mounts (pitch c from 675 mm to 850 mm)

Support for heavy 19" modules

Wide support surface

VLASTNOSTI PRODUKTU

Product Type: Slide Rail

Produktová řada: Eurorack

Materiál: Ocel

Povrchová úprava: Aluminum-Zinc Plated

Length: 560mm

Static Load: 40kg

Množství v balení: 1

Gross Weight: 2.26kg

DALŠÍ PODROBNOSTI O PRODUKTU

For rack-mounting from 800 mm depth only.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE