


Front Panel, Unshielded, Cutout for Coax Connectors, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGOVÉ ČÍSLO

30118-355

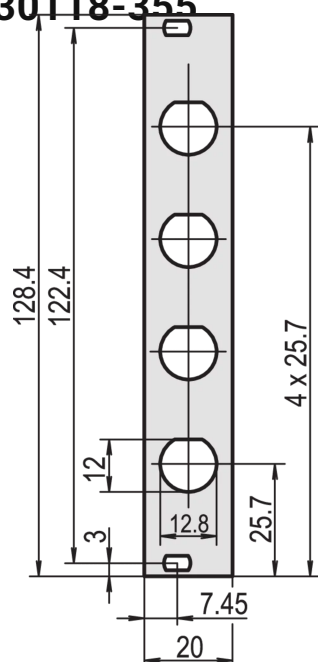

Aluminum, 2.5 mm, front anodized, conductive, unshielded version.

CERTIFICATIONS



VLASTNOSTI

Al, 2.5 mm, front anodized, conductive

3 U, 4 HP

Product Type: Front Panel
Typ: Front Panel without Handle
Accessory Type: Front panel
Mounting: Screw-on Front
EMC Shielding: No
Materiál: Hliník
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Rack Height: 3U
Výška (H): 128.4mm
Rack Width: 4HP
Šířka (W): 19.98mm
Hloubka (D): 2.5mm
Complies With: IEC 60297-3-101; IEEE 1101.1/10
Množství v balení: 1
Povrchová úprava: Anodized; Passivated
Net Weight: 0.013kg

Please order fixing material (sleeves, collar screws) separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE