


Plug-In Unit U-Profile Front Panel for IEL, IET, Type 2, 3 U, 12 HP, 0.1" Offset, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGOVÉ ČÍSLO

30848-432

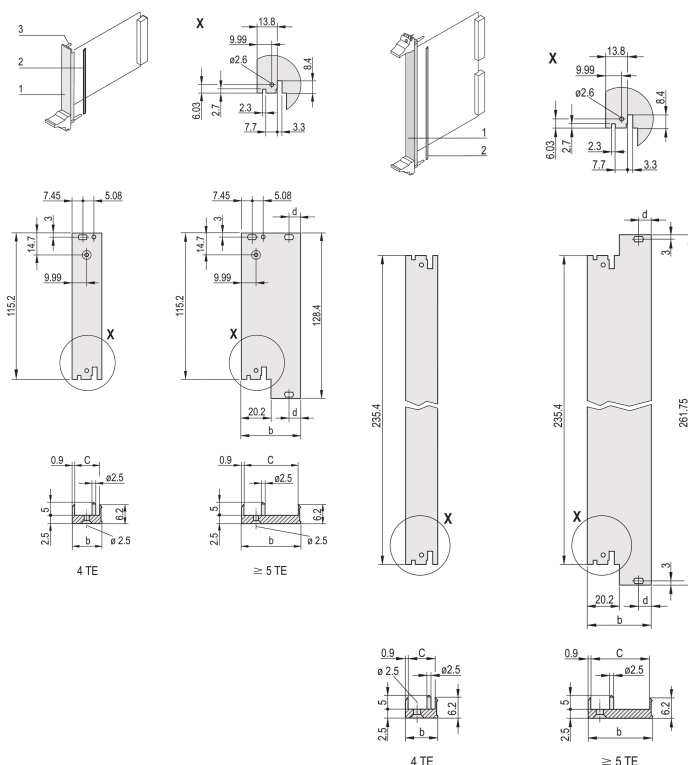

U-Profile front panel can be shielded with a textile gasket. It can be combined with the IEL and IET or the type 2 handle in trapezoid form, PCB mounting = 0,1" offset.

CERTIFICATIONS



VLASTNOSTI

Manufacturing process causes various surface structures to appear between 4 to 12 HP and 14 to 16 HP

Front panel, 3 U

Stainless steel alignment pin pressed-in

Al extrusion, 2.5 mm, front anodized, rear conductive

U-profile, shieldable with textile EMC gasket

For IEL/IET/Trapeziform Type 2 handle

For front mounting, PCB fixing with 0.1" offset

VLASTNOSTI PRODUKTU

Rack Width: 12HP

Množství v balení: 1

Accessory Type: Front panel

Typ rukojeti: IEL; IET

Mounting: Screw-on Front with 0.1" offset

EMC Gasket Type: Textile

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Complies With: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11

Hloubka: 2.5mm

EMC Shielding: No (Retrofittable)

Povrchová úprava: Anodized; Passivated

Výška: 128.4mm

Materiál: Hliník

Product Type: Front Panel

Rack Height: 3U

Typ: Front Panel for Handle (PIU)

Šířka: 60.6mm

DALŠÍ PODROBNOSTI O PRODUKTU

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE